

Product information

95 61 190

Wire Rope Cutter

Forged



MM

Double function: neat cutting, precise crimping

- With two crimping dies for end caps on Bowden cable sheaths and end ferrules for traction cables
- Comfortable work thanks to handy, slim design and internal opening spring
- Bolted joint for precise blade guidance, re-adjustable
- High leverage for reduced effort
- Cutting edge hardness approx. 64 HRC
- Chrome vanadium heavy-duty steel, forged, multi stage oil-hardened

General

Article No.	95 61 190
EAN	4003773040651
Head	polished
Handles	plastic coated
weight	310 g
Dimensions	190 x 60 x 20 mm
Reach	Nein
RohS	no


Technical details

Cutting capacity copper cable, multiple-stranded	10 mm ²
Cutting capacity copper cable, multiple-stranded (diameter)	Ø 7.0 mm
Cutting capacity copper cable, fine-stranded (diameter)	Ø 6.0 mm ²
Cutting capacities wire rope (diameter)	Ø 5.0 mm
Cutting capacities medium hard wire (diameter)	Ø 4.0 mm
Cutting capacities piano wire (diameter)	Ø 2.5 mm
Cutting capacities iron (diameter)	Ø 4 mm
AWG	8

Classification

eCl@ss 5.1.4	21040601
proficl@ss 6.0	AAC479c002
UNSPSC 13.1	23241616

technical change and errors excepted

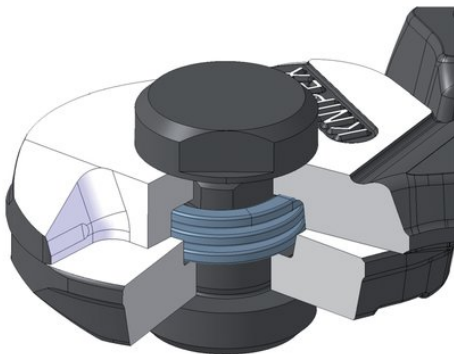

Internal opening spring