


PX0441/2M00 Datasheet

Product Name // Fully Overmoulded USB Cable PX0441
Series USB Standard A Plug To Sealed Mini B Plug 2M Cable

 [View Product Page](#)

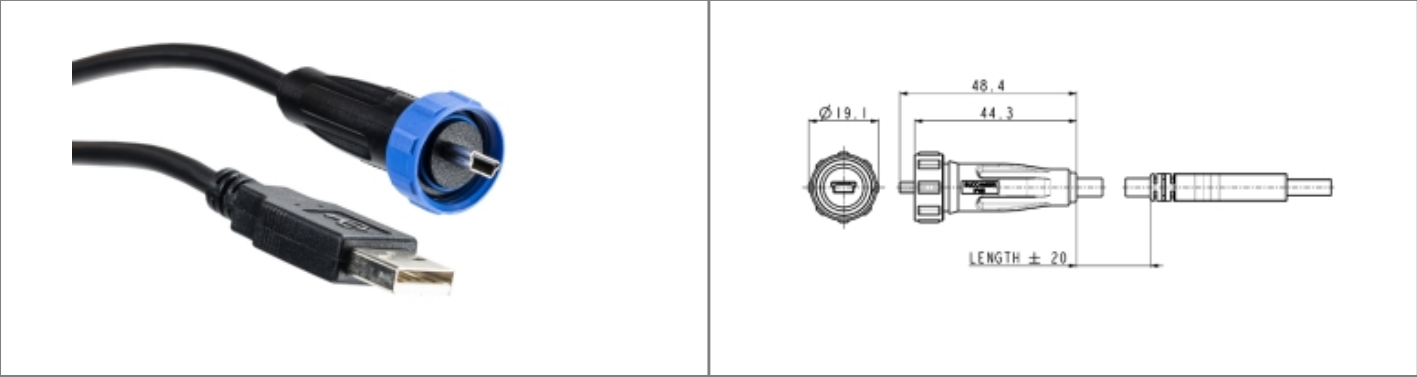

// Product Description:

- Pre-Wired Fully Overmoulded USB V2.0 Cable
- Water and dustproof to IP68 when mated with compatible connector
- Choice of:
- Standard USB Type A plug to Sealed Mini USB Type B plug (part codes prefixed PX0441)
- Mini USB Type A plug to Sealed Mini USB Type B plug (part codes prefixed PX0442)
- Mini USB Type B plug to Sealed Mini USB Type A plug (part codes prefixed PX0444)
- Choice of cable lengths depending on part code
- PX0485 Sealing Cap available separately to maintain IP rating of unmated connectors
- All connectors mate with PX0456, PX0457, PX0458. Additionally PX0441, PX0442 mate with PX0443, PX0446, PX0447

// General Information:

Product Display Title:	Pre-Wired Fully Overmoulded USB V2.0 Cable
Product Family:	Circular Data Connectors
Product Series:	400 Series - Mini USB Buccaneer
Change Notes:	PRODUCT-MOQ-ADJUSTMENT
Approvals:	CSA, UL, VDE
Body Material:	PVC
Cable Length:	2m
Contact Type:	Plug Contact
Coupling Type:	Screw
Current Max:	1A
Data Cable Type:	USB Standard A Plug To Sealed Mini B Plug
Diameter Over Coupling Ring Mm:	19.1mm
Flamability Rating:	UL94V-0
Function:	Flex to Standard Connector Double Ended Cable
Ip Rating:	IP68, IP69K
Max Operating Temperature:	+70°C
Min Operating Temperature:	0°C
Number Of Contacts:	5 Contacts
Voltage Max:	42V

// Product PDF Links

 [400 Series USB connectors product...](#)

// Product 3D CAD Model Links

 [PX0441/2M003D CAD Model](#)



Have a question or project enquiry
you'd like to talk to us about?



[Click Here To Contact Us](#)