


PX0839/PC Datasheet

Product Name // Rear Panel Mount Connector PX0839
Series CAT5e Shielded Socket Straight PCB Pins

 [View Product Page](#)

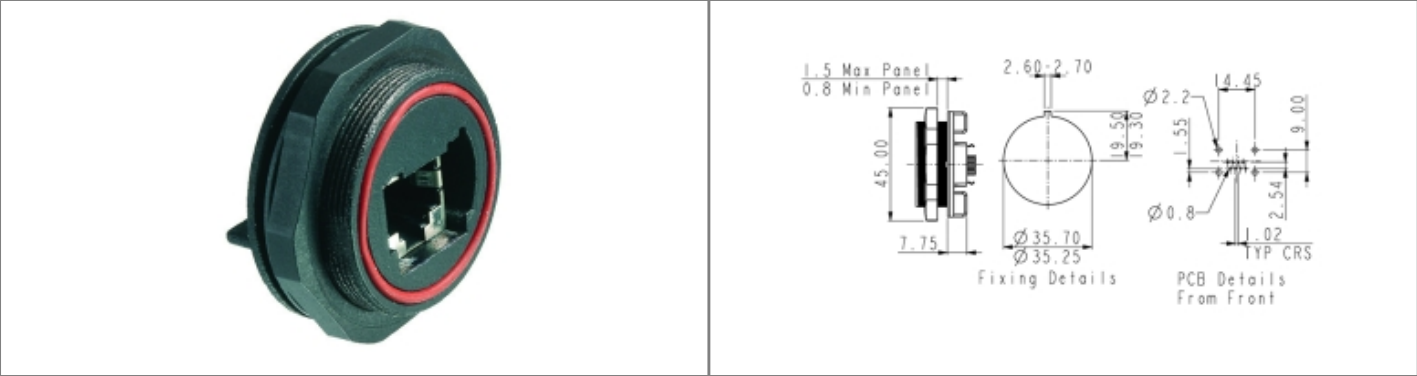

// Product Description:

- ⬢ Rear Panel Mount Connector
 - ⬢ Water and dustproof to IP68 when mated with compatible connector
 - ⬢ CAT5e shielded socket
 - ⬢ Supplied with panel sealing gasket
 - ⬢ Choice of Termination:
- ⬢ PX0839/PC has straight PCB pins, for direct vertical mounting to PCB
 - ⬢ PX0839/90 has 90 degree PCB pins, for direct horizontal mounting to PCB
 - ⬢ PX0839/IDC has two IDC blocks, for discrete termination
 - ⬢ PX0711 Sealing Cap available separately to maintain IP rating of unmated connectors
 - ⬢ Mates with PX0834, PX0836, PX0837, PX0838 Standard Series Flex Cable Connectors

// General Information:

Product Display Title:	Rear Panel Mount Connector
Product Family:	Circular Data Connectors
Product Series:	Standard Buccaneer - Ethernet
Body Material:	Polyester (PET)
Body Material Type:	Plastic Body
Contact Type:	Socket Contact
Coupling Type:	Screw
Current Max:	1.5A
Diameter Over Coupling Ring Mm:	38.1mm
Flamability Rating:	UL94V-0
Function:	Rear Panel Mount Connector
Ip Rating:	IP68, IP69K
Max Operating Temperature:	+70°C
Min Operating Temperature:	-20°C
Number Of Contacts:	8 Contacts
Voltage Max:	42V

// Product PDF Links

 [Standard Series Ethernet...](#)

// Product 3D CAD Model Links

 [PX0839/PC3D CAD Model](#)