


Technical datasheet: KPMB-G2224P-K6409S

Specifications:

Operating Temperature	-20°C to +60°C
Storage Temperature	-30°C to +70°C
Rated Voltage	24VDC
Operating Voltage	15V~27VDC
Max.Rated Current	30mA
Resonant Frequency	400Hz±100Hz
Min SPL	75dB at 24VDC/20cm
Response Time	50ms
Tone Nature	Continues
Weight	10g
Case Material/Color	ABS/Black

Dimensions:

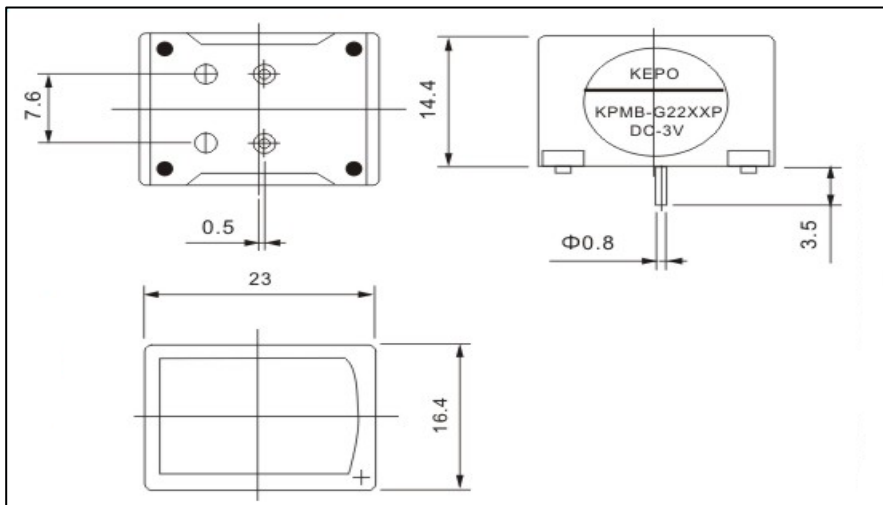

Frequency Response

