


# PCB TERMINAL BLOCKS

## 5.08mm PCB Mounting Double Decker Terminal Blocks

- Space saving
- Double decker
- 4(2x2) and 6(2x3) pole interlocking
- Open ended modules
- Professional rising clamp terminals
- Guided pin alignment
- Available pre-assembled
- Polarised mouldings
-  approved

CTBDD93HJ




### SPECIFICATION

Rating	20A/320V UL=12A/300V, VDE&IMQ=20A/320V
Dielectric strength	≥2.5kV
Impulse withstand voltage	4kV
Working temperature	110°C
Moulding	UL94-V0 flame retardant PA
Pin/terminal	Copper alloy, NI & SN

### Horizontal 5.08mm

TYPE NO.	POLES	LENGTH
CTBDD93HJ/2	4	12.7mm
CTBDD93HJ/3	6	17.8mm
CTBDD93HJ/4	8	22.9mm
CTBDD93HJ/5	10	27.9mm
CTBDD93HJ/6	12	33mm
CTBDD93HJ/7	14	38.1mm
CTBDD93HJ/8	16	43.2mm
CTBDD93HJ/9	18	48.3mm
CTBDD93HJ/10	20	53.3mm
CTBDD93HJ/11	22	58.4mm
CTBDD93HJ/12	24	63.5mm

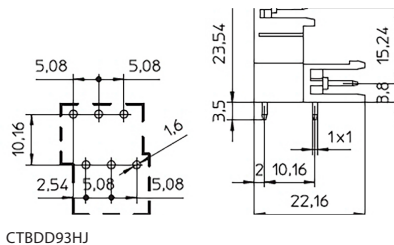

CTBDD93HJ

PCB  
TERMINAL  
BLOCKS

INTER-  
CONNECTION

FUSES &  
FUSE-  
HOLDERS

LEDs &  
INDICATORS

MINIATURE  
SWITCHES

LIMIT &  
SAFETY  
SWITCHES

CONTROL  
PRODUCTS

INTERFACE  
MODULES &  
SUPPORTS

RELAY  
BASES

DIN RAIL  
ENCLOSURES

BATTERIES

SOLAR  
PANELS

TRANS-  
FORMERS



+44 (0)1638 716101  
info@camdenboss.com  
www.camdenboss.com

We operate a constant improvement policy, our products are subject to change without notice.

Ver 1.1

