



# Round 35V DC 10 mA Pulse Switches

**Black** Order code: **50-1077**

**White** Order code: **50-1079**

### Mechanical properties:

Operating force

Hub

## Material

- Lower part

- Button

- Contact

Contact type

1,3N (130gr)  $\pm 30\%$


0,8mm

PBT

ABS

Silver plated

Self cleaning

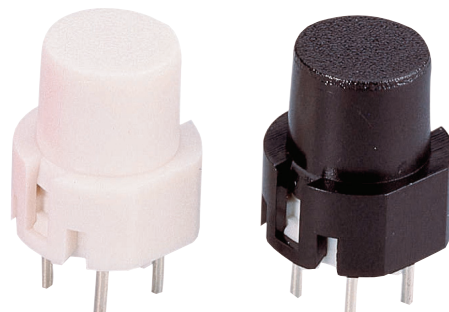

### Electrical properties:

Maximum switching voltage

Maximum switching current

Maximum switching power

### Contact resistance

## Insulation resistance

## Capacity between contacts

Life span

100V<sub>~</sub>


100mA

6VA

 $\leq 100\text{m}\Omega$  $10.10^5 \text{ M}\Omega$ 

1pF

250,000 cycles

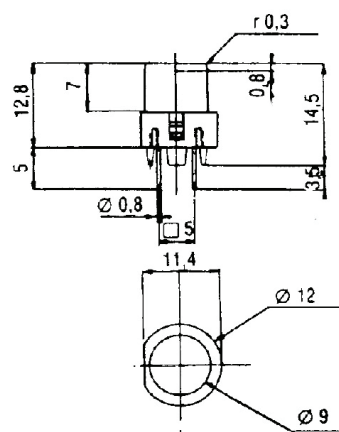

### Climatic properties:

Temperature range

## Climate testing

## Lightproof

-20°C to +85°C

21 days/40C

235°C during 5 seconds