




Color: ■

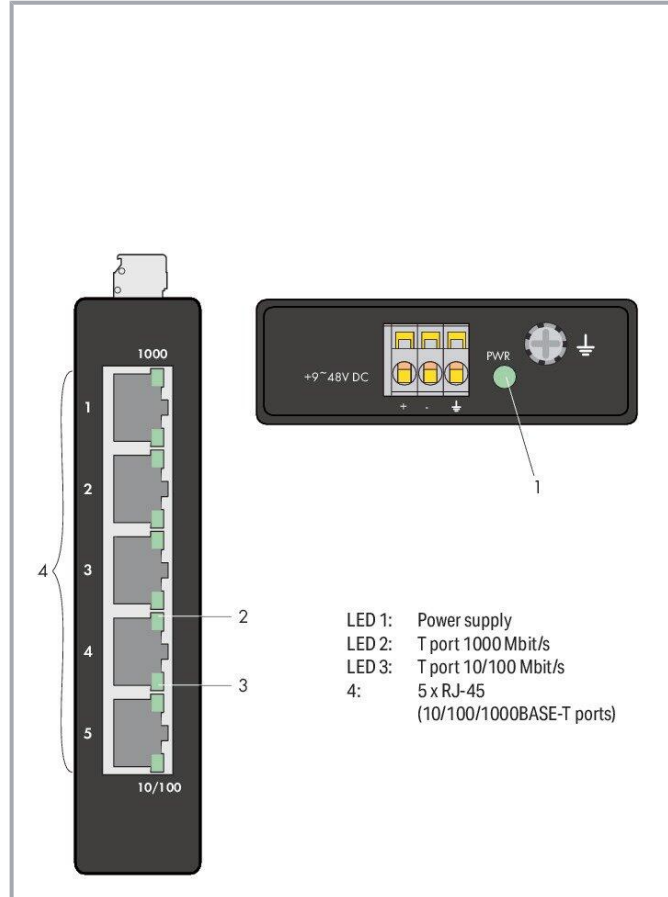

**X** This item has been discontinued and is no longer available as of 01.04.2024.

**Successor model**

Subject to changes. Please also observe the further product documentation!

WAGO GmbH & Co. KG  
Hansastr. 27  
32423 Minden  
Phone: +49571 887-0 | Fax: +49571 887-169  
Email: [info.de@wago.com](mailto:info.de@wago.com) | Web: [www.wago.com](http://www.wago.com)

Do you have any questions about our products?  
We are always happy to take your call at +49 (571) 887-44222.



Item no.852-1111/000-001  
Industrial-ECO-Switch; 5-port 1000Base-T; black

[www.wago.com/852-1111/000-001](http://www.wago.com/852-1111/000-001)

## Item description

This unmanaged industrial ETHERNET switch (852-1111) has 5 Gigabit ETHERNET ports for easily setting up small- to medium-sized networks. Its slim design paired with a DIN-rail adapter simplifies installation in the control cabinet and provides high vibration and shock resistance. Additionally, automatic transmission rate detection (auto-negotiation) and automatic identification of the transmit and receive lines (Auto MDI-X) allow simple plug-and-play operation, saving time and money during commissioning.

## Features:

- 5 ETHERNET ports 10/100/1000 Mbit/s Autonegotiation
- Front-panel diagnostic LEDs
- Supports Auto-MDI/MDI-X functions
- Full/half-duplex transfer modes for each port
- Store-and-forward switching method
- Integrated address look-up table, supports up to 8000 absolute MAC addresses
- Overvoltage protection
- Data flow control, per IEEE 802.3x Flow Control, in full-duplex mode
- Prioritization of ETHERNET data packets (PROFINET protocol, EtherType=0x8892) per IEEE802.1p
- DIN-35 rail mounting

## Data

### Technical data

Switching mode	Store-and-forward; non-blocking
Number of 1 Gbit/s ports	5
Communication standards	IEEE 802.3 10BASE-T IEEE 802.3u 100BASE-TX IEEE 802.3ab 1000BASE-T IEEE 802.3x Flow Control IEEE 802.1p Prioritization
MAC table (size)	8000 addresses
Jumbo frame size	9000. Byte
Supply voltage	9 ... 48 VDC
Power consumption (max.)	3 W
ESD (contact/air discharge)	4 KV / 8 KV
Baud rate	Copper cable: 10/1000 Mbit/s
Transmission medium (communication/fieldbus)	Copper cable: Cat. 5 or higher, 100 m maximum cable length

Subject to changes. Please also observe the further product documentation!

WAGO GmbH & Co. KG  
Hansastr. 27  
32423 Minden  
Phone: +49571 887-0 | Fax: +49571 887-169  
Email: [info.de@wago.com](mailto:info.de@wago.com) | Web: [www.wago.com](http://www.wago.com)

Do you have any questions about our products?  
We are always happy to take your call at +49 (571) 887-44222.



Topology	Star
Indicators	Device: LED (PWR) green: Power supply; per port: LED (100, 1000) green: Status 100 Mbps, 1000 Mbps ports 1 ... 5

### Connection data

Connection technology: communication/fieldbus	Copper cable: 5 x RJ-45
Connection technology: supply	1 x Built-in male connector: 231-433/001-000; included female connector (MCS Connectors): 231-103/026-000

### Physical data

Width	23.4 mm / 0.921 inches
Height	109.2 mm / 4.299 inches
Depth	73.8 mm / 2.906 inches
Depth from upper-edge of DIN-rail	81 mm / 3.189 inches

### Mechanical Data

Weight	190 g
Color	black
Housing material	Sheet steel
Conformity marking	CE

### Environmental requirements

Ambient temperature (operation)	-40 ... +70 °C
Surrounding air temperature (storage)	-40 ... +80 °C
Protection type	IP30
Relative humidity (without condensation)	95 %
Mounting type	DIN-35 rail
Vibration resistance	per IEC 60068-2-6
Shock resistance	per IEC 60068-2-27

### Commercial data

Product Group	27 (special components I/O)
eCl@ss 10.0	19-17-01-30
eCl@ss 9.0	19-17-01-06
ETIM 8.0	EC000734
ETIM 7.0	EC000734
PU (SPU)	1 pcs

Subject to changes. Please also observe the further product documentation!

WAGO GmbH & Co. KG  
 Hansastr. 27  
 32423 Minden  
 Phone: +49571 887-0 | Fax: +49571 887-169  
 Email: [info.de@wago.com](mailto:info.de@wago.com) | Web: [www.wago.com](http://www.wago.com)




Do you have any questions about our products?  
 We are always happy to take your call at +49 (571) 887-44222.




Packaging type	box
Country of origin	TW
GTIN	4066966216639
Customs tariff number	8517620000
End of Sale	2024-04-01
End of Production	2024-04-02
End of Delivery	2024-04-03
End of Service and Repair	2026-04-01

## Approvals / Certificates

### General approvals

Logo	Approval	Additional Approval Text	Certificate name
	<b>EAC</b> Brjansker Zertifizierungsstelle	TP TC 020/2011	EAC RU C-DE.AM02.B.00087/19
	<b>KC</b> National Radio Research Agency	Article 58-2, Clause 3	MSIP-REM-W43-ISW852
	<b>UL</b> Underwriters Laboratories Inc. (ORDINARY LOCATIONS)	UL 61010-2-201	E175199


### Approvals for marine applications

Logo	Approval	Additional Approval Text	Certificate name
	<b>DNV GL</b> Det Norske Veritas, Germanischer Lloyd	DNVGL-CG-339,Nov.2016	TAA0000239

## Optional accessories

### Cables and pluggable connectors

#### Connector plug

	<b>Item no.: 750-975</b> ETHERNET RJ-45 connector, IP20; ETHERNET 10/100 Mbit/s; for field assembly	<a href="http://www.wago.com/750-975">www.wago.com/750-975</a>
--	--	--

Subject to changes. Please also observe the further product documentation!



**Item no.: 750-976**  
PROFINET RJ-45 connector, IP20; ETHERNET 10/100 Mbit/s; for field assembly

[www.wago.com/750-976](http://www.wago.com/750-976)



**Item no.: 750-978/000-012**  
Connector ETHERNET; RJ-45; Cat. 6A; straight; Code T568B; AWG 22; Strain relief

[www.wago.com/750-978/000-012](http://www.wago.com/750-978/000-012)



**Item no.: 750-979/000-012**  
Connector ETHERNET; RJ-45; Cat. 6A; angled; Code T568B; AWG 22; Strain relief

[www.wago.com/750-979/000-012](http://www.wago.com/750-979/000-012)



**Item no.: 750-978/000-021**  
Connector ETHERNET; RJ-45; Cat. 6A; straight; Code T568A; AWG 24; Strain relief

[www.wago.com/750-978/000-021](http://www.wago.com/750-978/000-021)



**Item no.: 750-979/000-022**  
Connector ETHERNET; RJ-45; Cat. 6A; angled; Code T568B; AWG 24; Strain relief

[www.wago.com/750-979/000-022](http://www.wago.com/750-979/000-022)



**Item no.: 750-978/000-022**  
Connector ETHERNET; RJ-45; Cat. 6A; straight; Code T568B; AWG 24; Strain relief

[www.wago.com/750-978/000-022](http://www.wago.com/750-978/000-022)



**Item no.: 750-979/000-011**  
Connector ETHERNET; RJ-45; Cat. 6A; angled; Code T568A; AWG 22; Strain relief

[www.wago.com/750-979/000-011](http://www.wago.com/750-979/000-011)



**Item no.: 750-979/000-013**  
Connector PROFINET; RJ-45; Cat. 6A; angled; AWG 22; Strain relief

[www.wago.com/750-979/000-013](http://www.wago.com/750-979/000-013)



**Item no.: 750-979/000-021**  
Connector ETHERNET; RJ-45; Cat. 6A; angled; Code T568A; AWG 24; Strain relief

[www.wago.com/750-979/000-021](http://www.wago.com/750-979/000-021)



**Item no.: 750-977/000-011**  
Connector ETHERNET; RJ-45; Cat. 6A; straight; Code T568A; AWG 22

[www.wago.com/750-977/000-011](http://www.wago.com/750-977/000-011)



**Item no.: 750-978/000-013**  
Connector PROFINET; RJ-45; Cat. 6A; straight; AWG 22; Strain relief

[www.wago.com/750-978/000-013](http://www.wago.com/750-978/000-013)



**Item no.: 750-978/000-011**  
Connector ETHERNET; RJ-45; Cat. 6A; straight; Code T568A; AWG 22; Strain relief

[www.wago.com/750-978/000-011](http://www.wago.com/750-978/000-011)



**Item no.: 750-977/000-022**  
Connector ETHERNET; RJ-45; Cat. 6A; straight; Code T568B; AWG 24

[www.wago.com/750-977/000-022](http://www.wago.com/750-977/000-022)

Subject to changes. Please also observe the further product documentation!



**Item no.: 750-977/000-012**  
Connector ETHERNET; RJ-45; Cat. 6A; straight; Code T568B; AWG 22

[www.wago.com/750-977/000-012](http://www.wago.com/750-977/000-012)



**Item no.: 750-977/000-013**  
Connector PROFINET; RJ-45; Cat. 6A; straight; AWG 22

[www.wago.com/750-977/000-013](http://www.wago.com/750-977/000-013)



**Item no.: 750-977/000-021**  
Connector ETHERNET; RJ-45; Cat. 6A; straight; Code T568A; AWG 24

[www.wago.com/750-977/000-021](http://www.wago.com/750-977/000-021)

## Mounting

### Mounting accessories



**Item no.: 852-9101**  
DNV Carrier rail adapter; for ETHERNET Switches 852-1111/852-1111 marine approval; -

[www.wago.com/852-9101](http://www.wago.com/852-9101)

## Power supplies

### Power supply unit



**Item no.: 787-1722**  
Switched-mode power supply; Eco; 1-phase; 24 VDC output voltage; 5 A output current; DC-OK LED

[www.wago.com/787-1722](http://www.wago.com/787-1722)



**Item no.: 787-1712**  
Switched-mode power supply; Eco; 1-phase; 24 VDC output voltage; 2.5 A output current; DC-OK LED

[www.wago.com/787-1712](http://www.wago.com/787-1712)



**Item no.: 787-1702**  
Switched-mode power supply; Eco; 1-phase; 24 VDC output voltage; 1.25 A output current; DC-OK LED

[www.wago.com/787-1702](http://www.wago.com/787-1702)



**Item no.: 787-1102**  
Switched-mode power supply; Compact; 1-phase; 24 VDC output voltage; 1.3 A output current; DC-OK LED

[www.wago.com/787-1102](http://www.wago.com/787-1102)



**Item no.: 787-1226**  
Switched-mode power supply; Compact; 1-phase; 24 VDC output voltage; 6 A output current; DC-OK LED

[www.wago.com/787-1226](http://www.wago.com/787-1226)

## Interface module

### Interface module



**Item no.: 289-195**  
Interface module; RJ-45; IDC technology; Cat. 6; in mounting carrier; with shield connection

[www.wago.com/289-195](http://www.wago.com/289-195)



**Item no.: 289-175**  
Interface module; RJ-45; PCB terminal blocks, double-row; Cat. 5; in mounting carrier; with shield connection; with shield clamping saddle; 1,50 mm<sup>2</sup>

[www.wago.com/289-175](http://www.wago.com/289-175)



**Item no.: 289-172**  
Interface module; RJ-45; RJ-45; Cat. 5; in mounting carrier

[www.wago.com/289-172](http://www.wago.com/289-172)



**Item no.: 289-196**  
Interface module; RJ-45; with power jumper contacts; PCB terminal blocks; Cat. 5

[www.wago.com/289-196](http://www.wago.com/289-196)

Subject to changes. Please also observe the further product documentation!



## Downloads

### Documentation

#### Manual

Product Manual 5-Port 1000BASE-T Industrial ECO Switch	V 1.4.0 Dec 17, 2019	pdf 817.4 kB	Download
--	-------------------------	-----------------	----------

#### Bid Text

852-1111 X81 - Datei	Feb 19, 2019	xml 5.5 kB	Download
-------------------------	--------------	---------------	----------

852-1111 doc - Datei	Oct 9, 2017	doc 28.2 kB	Download
-------------------------	-------------	----------------	----------

ausschreiben.de 852-1111		URL	Download
--------------------------	--	-----	----------

#### System Description

Industrial Switches – General Product Information		pdf 1.9 MB	Download
---	--	---------------	----------

#### Additional Information

Disposal and Recycling Electrical and electronic equipment, Batteries, Packaging	V 1.1.0 Aug 18, 2022	pdf 2.2 MB	Download
---	-------------------------	---------------	----------

## CAD/CAE-Data

### CAD data

2D/3D Models 852-1111		URL	Download
-----------------------	--	-----	----------

### CAE data

EPLAN Data Portal 852-1111		URL	Download
----------------------------	--	-----	----------

WSCAD Universe 852-1111		URL	Download
-------------------------	--	-----	----------

ZUKEN Portal 852-1111		URL	Download
-----------------------	--	-----	----------

Subject to changes. Please also observe the further product documentation!

WAGO GmbH & Co. KG  
Hansastr. 27  
32423 Minden  
Phone: +49571 887-0 | Fax: +49571 887-169  
Email: [info.de@wago.com](mailto:info.de@wago.com) | Web: [www.wago.com](http://www.wago.com)

Do you have any questions about our products?  
We are always happy to take your call at +49 (571) 887-44222.



## Environmental Product Compliance

### Compliance Search

Environmental Product Compliance 852-1111  
Industrial-ECO-Switch; 5-port 1000Base-T; black

URL

Download

---

## Installation Notes

Subject to changes. Please also observe the further product documentation!