

## Product Name - Water Still with Stainless Steel Stand

Water Still EISCO Model - 4 SSI gives high quality distilled water with low conductivity and is pyrogen-free. The unit has built-in safety features like gate valve, flow switch, thermostat and fuse. The distilled output is cool ensured by high efficiency coiled condenser. Temperature of distillate is 25 - 40°C tested at ambient room temperature of 30°C.

Output 4 Ltr. / Hour


PH 5.5-6.0

Cooling Water Required 1-2 Ltr /min.

Minimum Pressure 3 p.s.i.

Net Weight 6 kg

## Manufacturers Code - CH0814

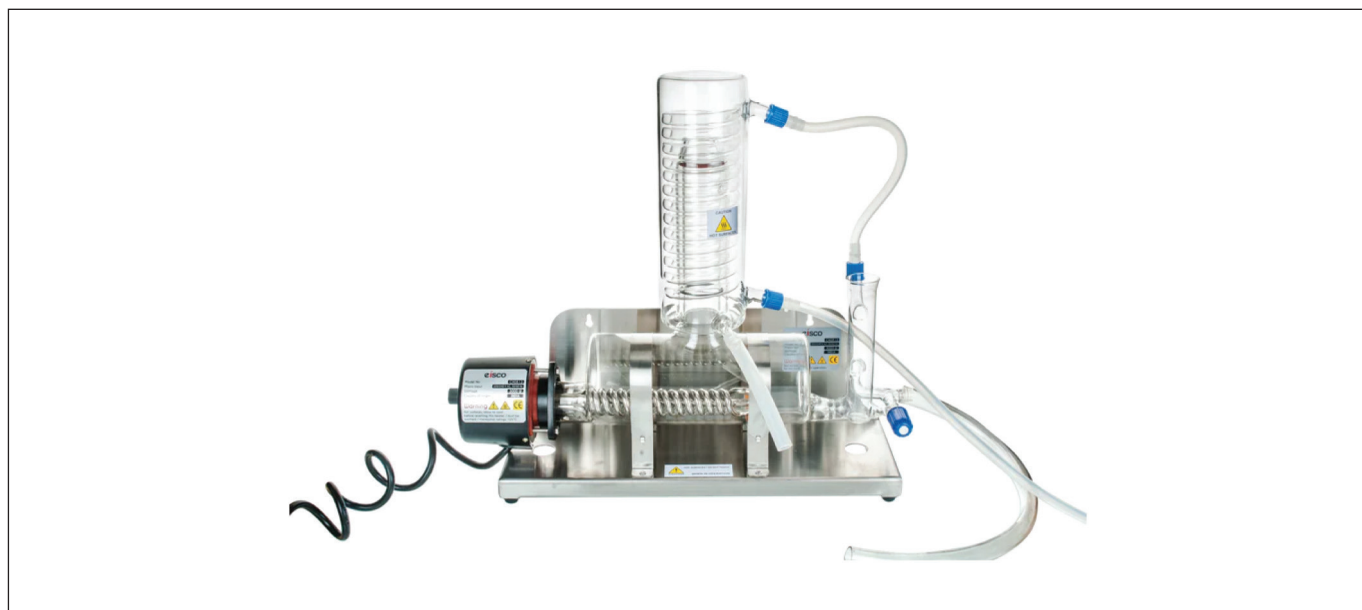

<b>Brand</b>	Eisco
<b>Weight</b>	4800 gm
<b>Dimension</b>	20.3 x 27.9 x 30.5
<b>Country of Origin</b>	India