


## Graduated Cylinders - Glass, Class-B with Hexagonal base

### CH0345D-WT

GLASS  
BORO  
3.3

ISO  
4788

Chemical  
Resistant

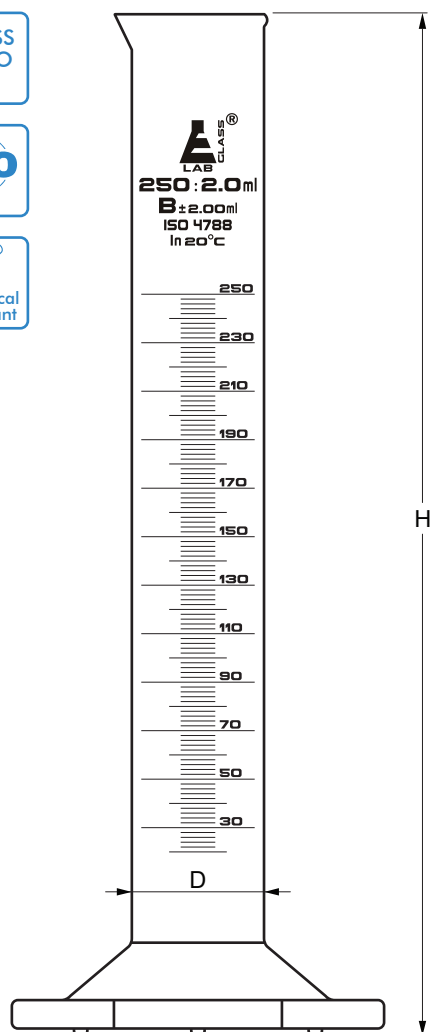

Capacity	250 ml
Sub. Division (ml)	2.0 ml
Tolerance	± 2.00 ml
Overall Height (H)	245 mm
Outer Dia. (D)	32 mm
Max. recommended temperature	250°C

- Class-B graduated cylinder with hexagonal base and spout
- Made of borosilicate glass 3.3
- Meets ISO 4788 standard
- Uniform wall thickness no wedge errors
- Chemical resistant white printing