


Graduated Measuring Cylinder - Glass, Class-B with Round base

CH0344F

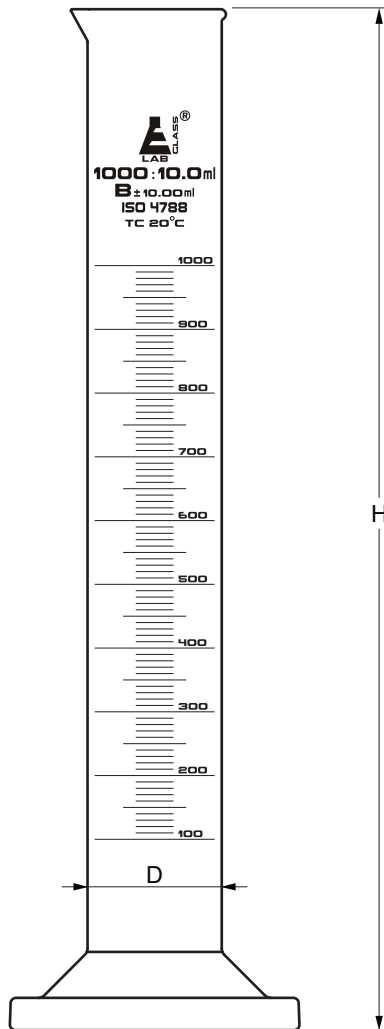

Capacity	1000 ml
Sub. Division (ml)	10.0 ml
Tolerance	± 10.0 ml
Overall Height (H)	450 mm
Outer Dia. (D)	68 mm
Max. recommended temperature	250°C

- Class-B graduated cylinder with round base and spout
- Made of borosilicate glass 3.3
- Meets ISO 4788 standard and accuracy as per DIN ISO 385
- Uniform wall thickness no wedge errors
- Chemical resistant blue printing