


| Art.-<br>No.                                   | Bemessungswerte/Ratings/Valeurs assignées<br>Strom<br>Current<br>Courant | Spannung<br>Voltage<br>Tension | Ausschaltvermögen<br>Breaking capacity<br>Pouvoir de coupure | Spannungsfall<br>Voltage drop<br>Chute de tension<br>max [mV] | Verlustleistung<br>Sustained dissip.<br>Valeur de dissip.<br>max.[W] | Schmelzintegral<br>Melting integral<br>Intégral de fusion<br>[A <sup>2</sup> s] |
|------------------------------------------------|--------------------------------------------------------------------------|--------------------------------|--------------------------------------------------------------|---------------------------------------------------------------|----------------------------------------------------------------------|---------------------------------------------------------------------------------|
| 632.602 <sup>1)</sup><br>632.603 <sup>1)</sup> | 32 mA<br>40 mA                                                           | 250 V                          | 35 A                                                         | auf Anfrage /                                                 | on request /                                                         | à demande                                                                       |
| 632.604                                        | 50 mA                                                                    |                                |                                                              | 10.000                                                        | 1,6                                                                  | 0,00125                                                                         |
| 632.605                                        | 63 mA                                                                    |                                |                                                              | 8.000                                                         |                                                                      | 0,00167                                                                         |
| 632.606                                        | 80 mA                                                                    |                                |                                                              | 7.000                                                         |                                                                      | 0,00128                                                                         |
| 632.607                                        | 100 mA                                                                   |                                |                                                              | 6.000                                                         |                                                                      | 0,00200                                                                         |
| 632.608                                        | 125 mA                                                                   |                                |                                                              | 5.500                                                         |                                                                      | 0,00469                                                                         |
| 632.609                                        | 160 mA                                                                   |                                |                                                              | 5.000                                                         |                                                                      | 0,00870                                                                         |
| 632.610                                        | 200 mA                                                                   |                                |                                                              | 4.000                                                         |                                                                      | 0,02000                                                                         |
| 632.611                                        | 250 mA                                                                   |                                |                                                              | 3.500                                                         |                                                                      | 0,03250                                                                         |
| 632.612                                        | 315 mA                                                                   |                                |                                                              | 3.000                                                         |                                                                      | 0,06747                                                                         |
| 632.613                                        | 400 mA                                                                   |                                |                                                              | 2.500                                                         |                                                                      | 0,15                                                                            |
| 632.614                                        | 500 mA                                                                   |                                |                                                              | 2.000                                                         |                                                                      | 0,28                                                                            |
| 632.615                                        | 630 mA                                                                   |                                |                                                              | 1.800                                                         |                                                                      | 0,47                                                                            |
| 632.616                                        | 800 mA                                                                   |                                |                                                              | 1.500                                                         |                                                                      | 0,54                                                                            |
| 632.617                                        | 1 A                                                                      |                                |                                                              | 500                                                           |                                                                      | 0,52                                                                            |
| 632.618                                        | 1,25 A                                                                   |                                |                                                              | 400                                                           | 2,5                                                                  | 2,66                                                                            |
| 632.619                                        | 1,6 A                                                                    |                                |                                                              | 400                                                           |                                                                      | 5,32                                                                            |
| 632.620                                        | 2 A                                                                      |                                |                                                              | 300                                                           |                                                                      | 9,52                                                                            |
| 632.621                                        | 2,5 A                                                                    | 150 V                          |                                                              | 250                                                           |                                                                      | 19,75                                                                           |
| 632.622                                        | 3,15 A                                                                   | 150 V                          | 40 A                                                         | 250                                                           | 4                                                                    | 25,60                                                                           |
| 632.623                                        | 4 A                                                                      | 150 V                          |                                                              | 250                                                           |                                                                      | 51,20                                                                           |
| 632.624                                        | 5 A                                                                      | 60 V                           |                                                              | 200                                                           |                                                                      | 65,50                                                                           |
| 632.625                                        | 6,3 A                                                                    | 60 V                           |                                                              | 200                                                           |                                                                      | 103,99                                                                          |
| 632.626                                        | 8 A                                                                      | 60 V                           |                                                              | 200                                                           |                                                                      | 206,08                                                                          |
| 632.627                                        | 10 A                                                                     | 60 V                           |                                                              | 200                                                           |                                                                      | 260,00                                                                          |
| 632.628 <sup>1)</sup><br>632.630 <sup>1)</sup> | 12,5 A<br>16 A                                                           | 60 V<br>60 V                   | 100 A                                                        | auf Anfrage /                                                 | on request /                                                         | à demande                                                                       |

Aufbau: Glasrohr, durchsichtig  
Kontaktkappen: Messing, vernickelt  
Verpackung: 100 St. = 10 x 10 Faltschachteln  
500 St. = Industrieverpackung

Construction: Glasstube, transparent  
Contact caps: Brass, nickel plated  
Packing: 100 pcs. = 10 boxes of 10 pieces  
500 pcs. = Industrial boxes

Construction: Tube verre, transparent  
Cabochons de contact: Laiton, nickelé  
Emballage: 100 pcs. = en 10 boîtes de 10 pièces  
500 pcs. = en emballage industriel

Strom-Zeit-Kennlinien  
Current Time Characteristics  
Caractéristique courant/temps

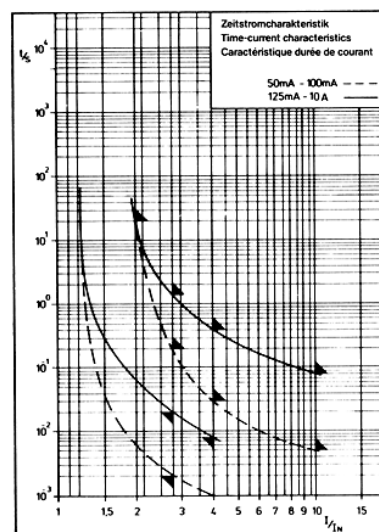

Schmelzzeit-Grenzwerte / Pre-arcing time limits / Temps de fusion limité

| Bemessungsstrom<br>Rated current<br>Courant assigné | 2,0 I <sub>rat</sub><br>max. | 2,75 I <sub>rat</sub><br>min. max. | 4 I <sub>rat</sub><br>min. max. | 10 I <sub>rat</sub><br>max. |
|-----------------------------------------------------|------------------------------|------------------------------------|---------------------------------|-----------------------------|
| 50 - 100 mA                                         | 20 s                         | 2 ms 200 ms                        | 1 ms 30 ms                      | 5 ms                        |
| 125 mA - 10 A                                       | 20 s                         | 20 ms 1.500 ms                     | 8 ms 400 ms                     | 80 ms                       |

1) Nicht in der Normenreihe verzeichnet / Not mentioned in the standards / Pas mentionné dans la norme.