

EAO – Your Expert Partner for Human Machine Interfaces

45-2C36.1A20.000 - Emergency-stop switch actuator, foolproof EN IEC 60947-5-5

45-2C36.1A20.000 - Emergency-stop switch actuator, foolproof EN IEC 60947-5-5



Attention: The preview is based on a sample product. This can differ from your current configuration.

Mounting

Mounting cut-out	Ø 22.5 mm
Design	raised

Front

Front shape	round
Front dimension	Ø 60 mm
Front ring material	Plastic
Front ring colour	black

Other Attributes

Weight	0.056 kg
--------	----------

Operating-/Indication part

Lens optics	opaque
Lens material	Plastic
Lens colour	red
Lens profile	Mushroom
Lens illumination	non-illuminative

IP-Rating

Front protection	IP66, IP67, IP69K
------------------	-------------------

Actuator

Switching action	Maintained
Housing material	Plastic

Switching element

max. number of switching elements	6
-----------------------------------	---


Function

Emergency stop switch


EAO – Your Expert Partner for Human Machine Interfaces

45-2C36.1A20.000 - Emergency-stop switch actuator, foolproof EN IEC 60947-5-5


Dimensions

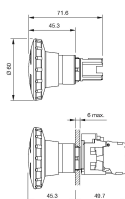

Mounting cut-outs

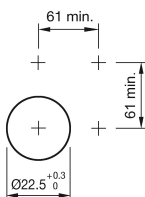

Wiring diagram

 

Additional information

Application as per DIN EN ISO 13850 and EN 60204-1
twist to release

Legend

Switching action: C = Maintained