


data sheet **CLIXX ..**

product	cable entry with membrane and strain relief
properties	<ul style="list-style-type: none"> - Space-saving: Flat construction form, minimal space requirement – can also be used in large quantities in extremely small spaces - Easiest assembly: External mounting from one side only – no thread, no tools or locknuts required - Time-saving: Simple one-hand-only assembly reduces installation time by 80 % - Numerous applications: For a diverse range of cable types without special sealings, protection class and strain relief not affected, without a cable installed Clixx can be used as a seal.
material	polypropylene and themoplastic elastomeric
colour	grey - RAL 7035
protection specification	IP 66/67
temperature range	-40°C to 80°C

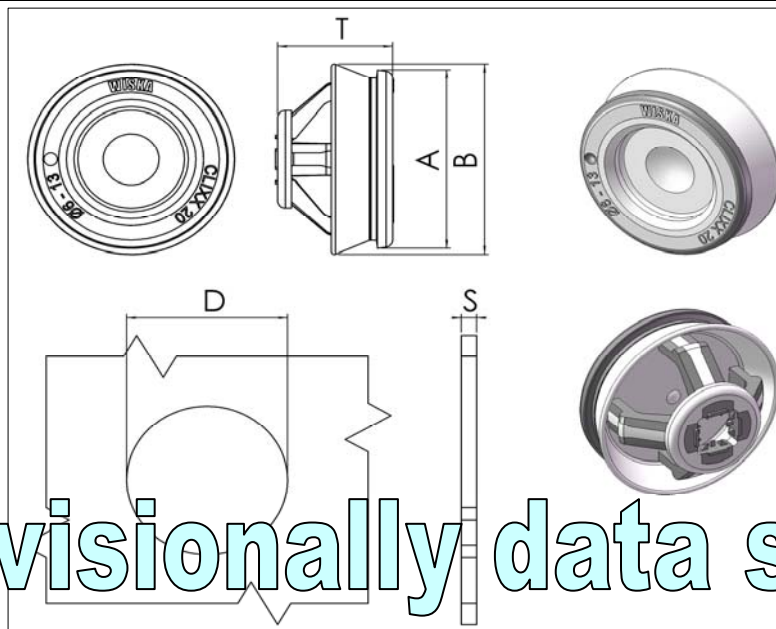

provisionally data sheet

type	enclosures hole size		enclosures wall thickness		anchorage range = sealing range acc. to EN 50262 [mm]	type of cable anchorage acc. to EN 50262 (tested on cables)	collar diameter fitting [mm]	collar diameter sealing [mm]	total length [mm]
	D [mm]	S min. [mm]	S max. [mm]						
CLIXX 12	in preparation- we inform you								
CLIXX 16	in preparation- we inform you								
CLIXX 20	20+0,7	0,8	3,5		6 - 13	A	25	32	15
CLIXX 25	in preparation- we inform you								
CLIXX 32	in preparation- we inform you								

The correctness of data has been made to the best of our knowledge and no responsibility is accepted. Technical improvement reserved. approval 2010-04-22; PGE