



BELL TRANSFORMER,
8VA PRIM 230-240V AC,50HZ,
SEK 8V,12V AC WITH PTC PROT.,2MW

Similar to image

Technical data:

Input voltage	V	230
Design of the transformer		standard bell transformer
Number of pitch units for width		2
Product function / thermoprotection		Yes
Characteristic feature of the output / short-circuit protected		Yes
Type of fixing/fixation / series installation		Yes
Active power loss / maximum	W	5.7
Suitability for integration / flush mounting		No
Output current / maximum	A	1
4		No
Output voltage / _1 / rated value	V	8
Output voltage / _2 / rated value	V	12
Output current / _1 / rated value	A	1
Output current / _2 / rated value	A	0.6
Length	mm	90
Width	mm	36
Height	mm	64
Active power supplied / maximum	W	8

Suitability for integration / surface-mounted installation

No

Certificates/approvals:

General Product Approval

Declaration of Conformity



Further information:

Information- and Downloadcenter (Catalogs, Brochures,...)

<http://www.siemens.com/lowvoltage/catalogs>

Industry Mall (Online ordering system)

<http://www.siemens.com/lowvoltage/mall>

Service&Support (Manuals, Certificates, Characteristics, FAQs,...)



<http://support.automation.siemens.com/WW/view/en/4AC3208-1/all>

Image database (product images, 2D dimension drawings, 3D models, device circuit diagrams, ...)

http://www.automation.siemens.com/bilddb/cax_en.aspx?mlfb=4AC3208-1

CAX-Online-Generator

<http://www.siemens.com/cax>

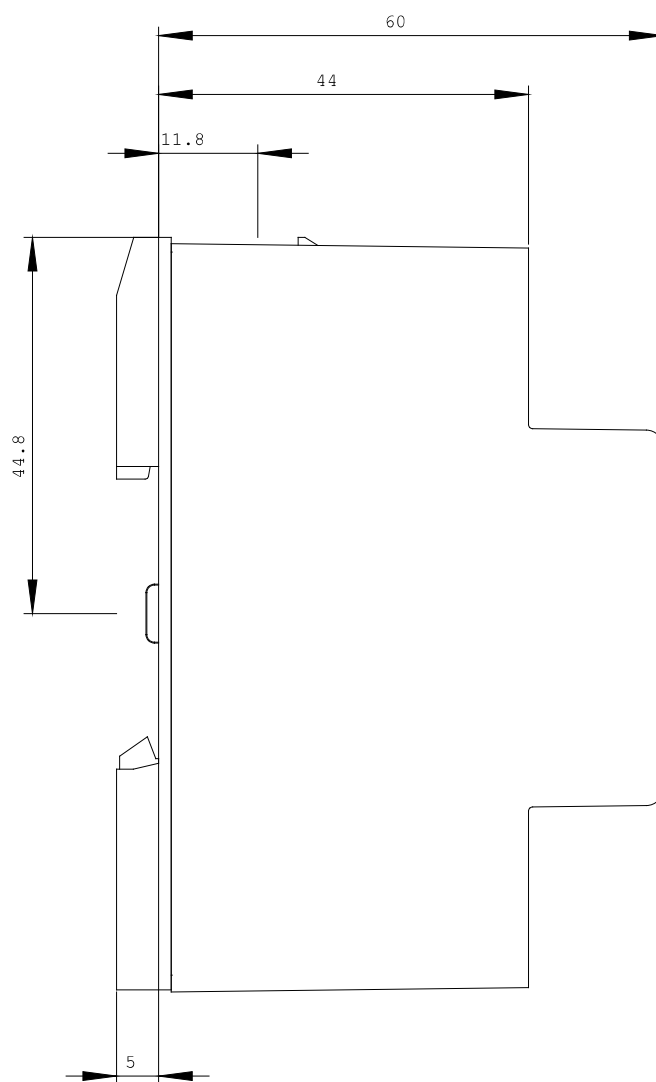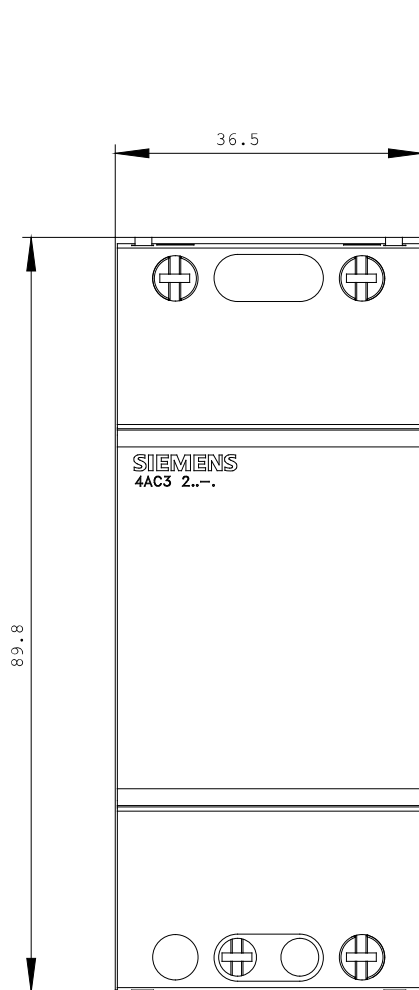

last change:

Oct 28, 2013