



Signal Towers

COMPRO LED-SIGNAL TOWERS CO ST 40 & CO ST 70

- | Flexible capabilities
- | Several combination possibilities
- | Impact-proof case
- | Sounder version available
- | Easy assembly



- Fire
- Security
- Industrial
- Railway
- Marine
- Optical
- Acoustic

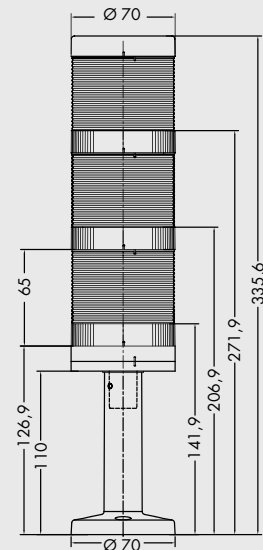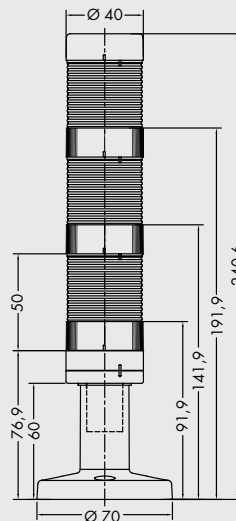

SPECIFICATIONS

Model	CO ST 40	CO ST 70
Operating Voltage	24 V AC/DC	24 V AC/DC / 230 V AC
Current consumption	45 mA	45 mA
Capabilities	continuous light	continuous light, flash light
IP rating	IP65	IP65
Operating temperature	-25°C to +70°C	-25°C to +70°C
Body colour	black	black
Lens colours	red, amber, green, blue, clear	red, amber, green, blue, clear
Construction	Lens: PC; Base: MPP0	Lens: PC; Base: MPP0

*NEW: 230 V-module
now available!*