


WIRE ROUTING, CLIPS AND CLAMPS


E

Part No.	"A" mm	"B" mm	"C" mm	"D" mm
TFCC-30-01	30.5	44.7	15.7	18.5
TFCC-40-01	50.8	67.1		15.7
TFCC-50-01	63.5	78.2		18.8
TFCC-64-01	83.5	97.5		16.0

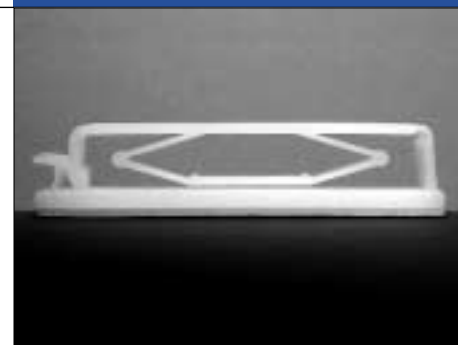

TFCC

TENSION FLAT CABLE CLAMP

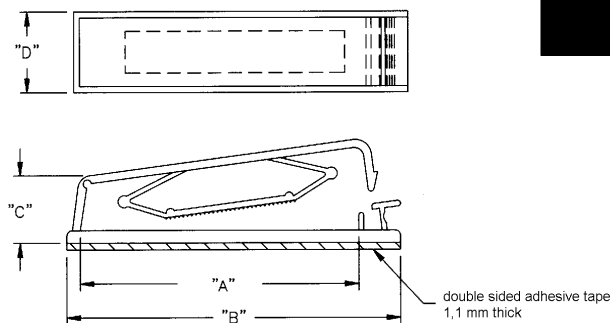

Material: Nylon 6/6 - natural, UL 94 V-2, RMS-01
 Adh. Tape: Working temperature -20°C – +50°C
 Std. Pk.: 100 pcs.

Note:

TFCC	30	01
Part	Size	Material Code