

Ball-pushrod valve for mechanical screw operator




A Wrench 17

- 1 = Supply port
- 2 - 4 = Use
- 3 - 5 = Exhaust
- 14 = Control
- 12 = Return

Weight: 0,066

Symbol	Control	Return	Part no.
	ball-pushrod	mechanical spring	E-15403A

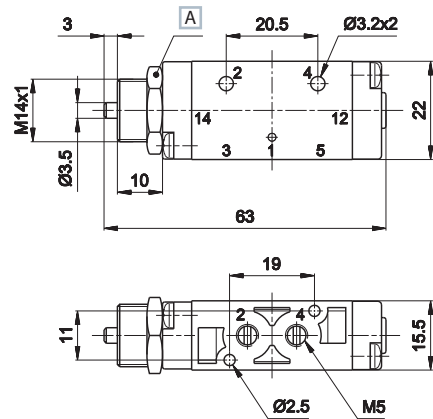

PNEUMATIC AND MECHANICAL ACTUATORS

	Pneumatic actuator	AI-3550	
	Amplified pneumatic actuator	AI-3551	
	Roller operator 1 position	AI-3560	
	Ball-push operator 1 position	AI-3562	
	Omni-directional operator	AI-3563	
	Roller lever operator 1 position	AI-3570	
	Articulated roller lever operator 1 position Complete actuation with stroke 2,5 mm max stroke 4,7 mm	AI-3571	
	Key operator 1 position	AI-3572	

MANUAL ACTUATORS

	Recessed button	<ul style="list-style-type: none"> ■BLACK AI-3511 ■RED AI-3512 ■GREEN AI-3513 	
	Head button	<ul style="list-style-type: none"> ■RED AI-3514 ■BLACK AI-3516 ■RED AI-3514D ■BLACK AI-3516D 	
	Button	<ul style="list-style-type: none"> ■GREEN AI-3515 ■RED AI-3517 ■BLACK AI-3519 	
	Rotating selector	<ul style="list-style-type: none"> ■BLACK AI-3520 ■BLACK AI-3521 	
	Rotating lever selector	<ul style="list-style-type: none"> ■BLACK AI-3522 ■BLACK AI-3523 	
	Lever	<ul style="list-style-type: none"> ■BLACK AI-3524 	
	Omni-directional operator	<ul style="list-style-type: none"> ■BLACK AI-3525 	
	Push-pull operator	<ul style="list-style-type: none"> ■BLACK AI-3526 	

For technical features of coils and connector, see section "Accessories>Buttons"