

Clip, 6.3x32 mm, 32 A, BeCu



600 VAC/DC · 32 A (UL)



Description

- BeCu Clip up to 32 A Application

Standards

- UL 4248-1
- CSA 22.2 no. 4248.1

Approvals

- UL File Number: E39328

Applications

- Photovoltaic

References

Fuseholder to [SUT 6.3x32](#)

Weblinks

[pdf datasheet](#), [html-datasheet](#), [General Product Information](#), [Packaging details](#), [Approvals](#), [CE declaration of conformity](#), [RoHS](#), [CHINA-RoHS](#), [REACH](#), [Distributor-Stock-Check](#), [Detailed request for product](#)


Technical Data

| | |
|------------------------------|------------------------------|
| Fuse-Link | 6.3 x 32mm |
| Mounting | PCB |
| Terminal | Solder THT |
| Rated Voltage | 600 VAC/DC |
| Rated current | 32 A (UL) |
| Admissible Ambient Air Temp. | -55 °C to 125 °C |
| Material: Terminals | BeCu |
| Storage Conditions | 0 °C to 60 °C, max. 70% r.h. |

| | |
|------------------------------|---|
| Soldering Methods | Wave Soldering Profile |
| Solderability | 235 °C / 2 sec acc. to IEC 60068-2-20, Test Ta, method 1 |
| Resistance to Soldering Heat | 260 °C / 10 sec acc. to IEC 60068-2-20, Test Tb, method 1A |
| Contact Resistance | ≤ 10 mΩ at 20 mV |

Dimension

8.2 mm

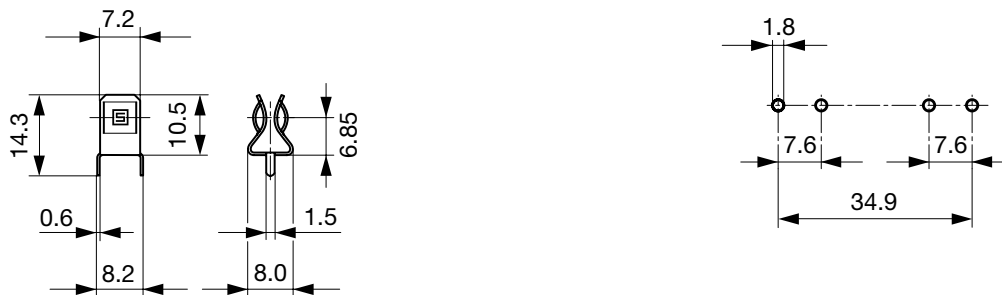

Drilling diagram

All Variants

| Clip | Material: Terminals | Order Number |
|------|--------------------------------|---------------------------|
| ● | Tin-plated Beryllium-Copper | 8040.0001 |
| ● | Silver-plated Beryllium-Copper | 8040.0003 |

Most Popular.

Availability for all products can be searched real-time: <http://www.schurter.com/Stock-Check/Stock-Check-SCHURTER>

Packaging Unit

Bulk (1000 pcs.)