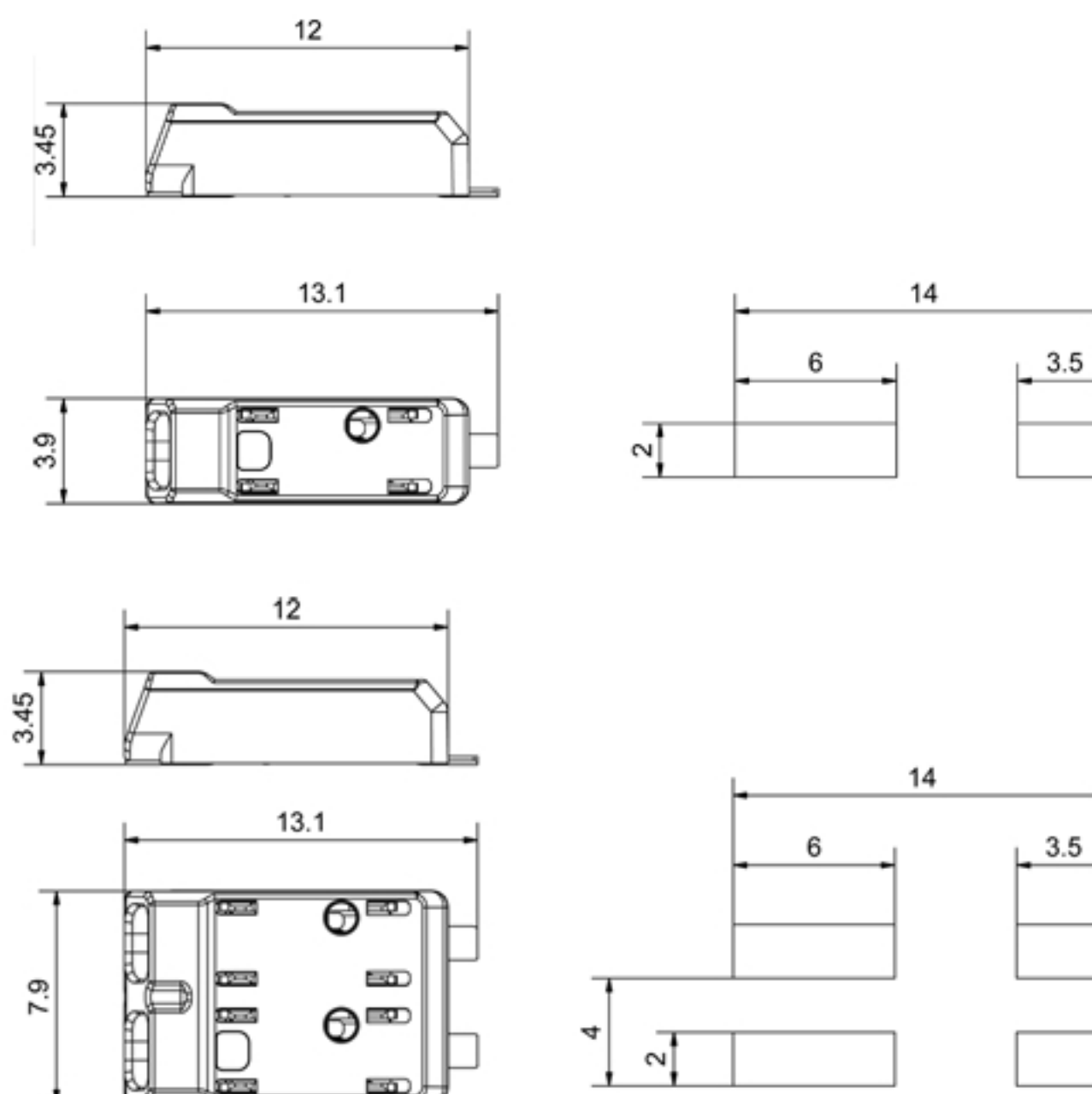


SMD Connectors for LED Modules

SMDFlat 345 Pin Spacing 4.0mm
 LED - SMD Connector


FEATURES

- * 3.45mm height, the lowest version in the market minimising formation of shades in application
- * Funnel shaped wiring ports for easy and automatic wire access of solid or flexible wires up to 0.75mm²
- * 1 and 2 pole versions
- * Tape and reel packaging for automatic process
- * Secure release function due to a release tool

TECHNICAL DETAILS

Connection	Clamping spring contacts Conductor size 0.2 – 0.75mm ² solid or flexible
Fixing	SMD
Mouldings	PPA-GF, white Flammability rating to UL94: V-0 Continuous working temp 150°C Short-time temp 200°C
Contacts	Spring steel, copper
Voltage rating	1 pole: 600V to EN 60598-1 2 pole: 250V to EN 60598-1
Current rating	To EN 60998: 9A(0.75mm ²) resp. 6A (0.5mm ²)
Lower temperature limit	-60°C
Upper temperature limit	105°C
Stripping length	8 – 9mm
Protection class	IP00
Packaging	Tape and reel

OPTIONS

Accessories - release tool WKZ

