



TM55 Pocket Fold-Up Food Thermometer

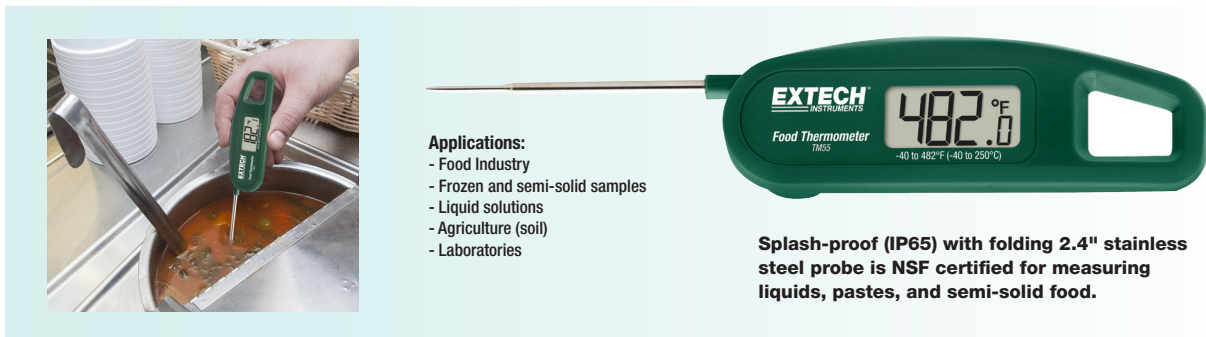

Features

- Measures from -40 to 482°F (-40 to 250°C) with 2.4" (61mm) stainless steel probe (NSF certified)
- Fast response time at < 5 seconds in moving liquid
- Large LCD display with 0.1° resolution
- Basic accuracy: $\pm 1^{\circ}\text{F}/0.5^{\circ}\text{C}$
- Auto power off (with disable) after 1 hour or when probe is placed in stored position
- Probe can be positioned from 0° (storage) to 180° angle
- Ultrasonically welded housing (waterproof IP65 rated) with anti-microbial additive
- Built-in magnetized strip attaches to refrigerator
- Dishwasher safe (top rack)
- Dimensions: 4.6x1.5x0.8" (116 x 38 x 20mm); Weight: 1.5oz (41.2g)
- Complete with CR2032 battery

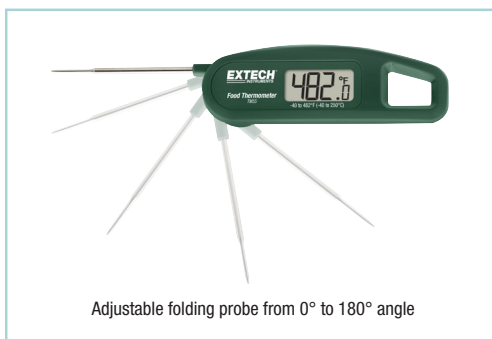

Ordering

TM55..... Pocket Fold-up Food Thermometer

