

FUSES & FUSEHOLDERS



5x20mm Glass and Ceramic Fuses


CAMFUSE Range

5x20mm Quick Blow Glass Fuses

TYPE NO.	RATING	TYPE NO.	RATING
CF0520F/100	100mA	CF0520F/1.6	1.6A
CF0520F/125	125mA	CF0520F/2	2A
CF0520F/160	160mA	CF0520F/2.5	2.5A
CF0520F/200	200mA	CF0520F/3	3A
CF0520F/250	250mA	CF0520F/3.15	3.15A
CF0520F/315	315mA	CF0520F/4	4A
CF0520F/400	400mA	CF0520F/5	5A
CF0520F/500	500mA	CF0520F/6.3	6.3A
CF0520F/630	630mA	CF0520F/8	8A
CF0520F/800	800mA	CF0520F/10	10A
CF0520F/1	1A	CF0520F/12.5	12.5A
CF0520F/1.25	1.25A	CF0520F/15	15A
		CF0520F/16	16A
		CF0520F/20	20A

- Quick blow (F) IEC60127
- Glass cartridge, nickel plated brass end caps
- Colour coded available
- Break capacity 35A or 10In 250VAC whichever is greater (125mA-16A)
- DC cold resistance: 64 ~ 96m
- Melting : 1.810A2.sec
- Maximum voltage drop (150mV max): 115m
- Break capacity 35A or 10In 250VAC whichever is greater (125mA-16A)
- BSI, , , & approved (210mA - 16A)

CF0520F

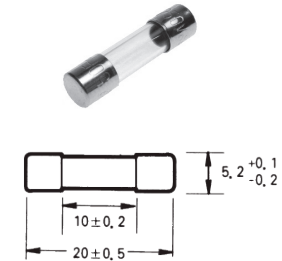


5x20mm Time Delay Glass Fuses

TYPE NO.	RATING	TYPE NO.	RATING
CF0520T/100	100mA	CF0520T/1	1A
CF0520T/125	125mA	CF0520T/1.25	1.25A
CF0520T/160	160mA	CF0520T/1.6	1.6A
CF0520T/200	200mA	CF0520T/2	2A
CF0520T/250	250mA	CF0520T/2.5	2.5A
CF0520T/315	315mA	CF0520T/3.15	3.15A
CF0520T/400	400mA	CF0520T/4	4A
CF0520T/500	500mA	CF0520T/5	5A
CF0520T/630	630mA	CF0520T/6.3	6.3A
CF0520T/800	800mA	CF0520T/8	8A
		CF0520T/10	10A
		CF0520T/12.5	12.5A

- Time delay (F) IEC60127
- Glass cartridge, nickel plated end caps-Brass
- , , & approved (210mA-16A)

CF0520T

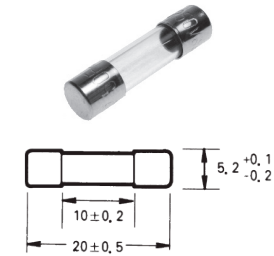


5x20mm Quick Blow Ceramic Fuses

TYPE NO.	RATING	TYPE NO.	RATING
CF0521CF/100	100mA	CF0521CF/1.25	1.25A
CF0521CF/125	125mA	CF0521CF/1.6	1.6A
CF0521CF/160	160mA	CF0521CF/2	2A
CF0521CF/200	200mA	CF0521CF/2.5	2.5A
CF0521CF/250	250mA	CF0521CF/3.15	3.15A
CF0521CF/315	315mA	CF0521CF/4	4A
CF0521CF/400	400mA	CF0521CF/5	5A
CF0521CF/500	500mA	CF0521CF/6.3	6.3A
CF0521CF/630	630mA	CF0521CF/7.5	7.5A
CF0521CF/800	800mA	CF0521CF/8	8A
CF0521CF/1	1A	CF0521CF/10	10A
		CF0521CF/12.5	12.5A

- Quick blow (F) IEC60127
- Ceramic cartridge, nickel plated brass end caps
- Sand filled
- BSI, , & approved (250mA - 12.5A)

CF0521CF

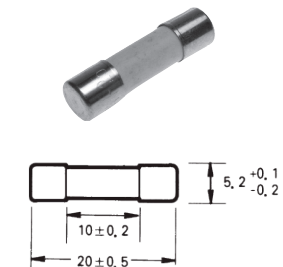


5x20mm Time Delay Ceramic Fuses

TYPE NO.	RATING	TYPE NO.	RATING
CF0521CT/125	125mA	CF0521CT/1.25	1.25A
CF0521CT/160	160mA	CF0521CT/1.6	1.6A
CF0521CT/200	200mA	CF0521CT/2	2A
CF0521CT/250	250mA	CF0521CT/2.5	2.5A
CF0521CT/315	315mA	CF0521CT/3.15	3.15A
CF0521CT/400	400mA	CF0521CT/4	4A
CF0521CT/500	500mA	CF0521CT/5	5A
CF0521CT/630	630mA	CF0521CT/6.3	6.3A
CF0521CT/800	800mA	CF0521CT/7.5	7.5A
CF0521CT/1	1A	CF0521CT/8	8A
		CF0521CT/10	10A
		CF0521CT/12.5	12.5A

- Time delay (T) IEC60127-2/5
- Ceramic cartridge, nickel plated brass end caps
- Sand filled
- BSI, , , & approved (200mA - 12.5A)

CF0521CT

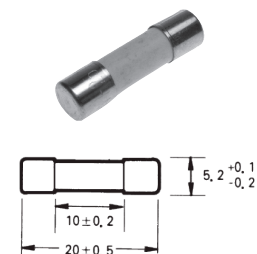

PCB
TERMINAL
BLOCKS

INTER-
CONNECTION

FUSES &
FUSE-
HOLDERS

LEDs &
INDICATORS

MINIATURE
SWITCHES

LIMIT &
SAFETY
SWITCHES

CONTROL
PRODUCTS

INTERFACE
MODULES &
SUPPORTS

RELAY
BASES

DIN RAIL
ENCLOSURES

BATTERIES


SOLAR
PANELS

TRANS-
FORMERS

FUSES & FUSEHOLDERS


CF0520F & CFB0520F

Average Time Current (I-T Curves)

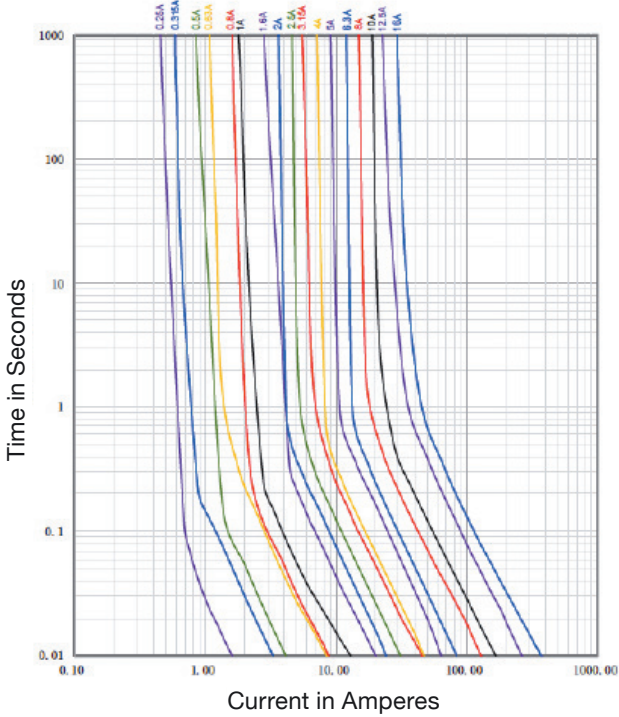


CF0520T & CFB0520T

Average Time Current (I-T Curves)

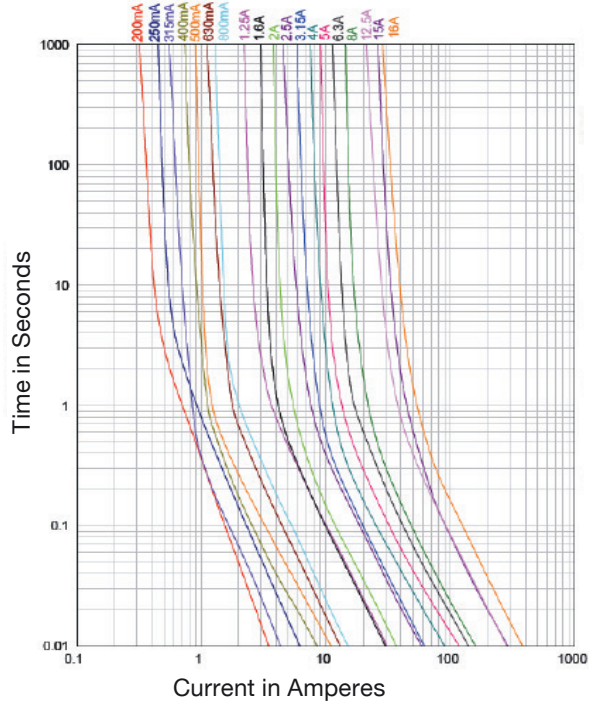


CF0521CF & CFB0521CF

Average Time Current (I-T Curves)

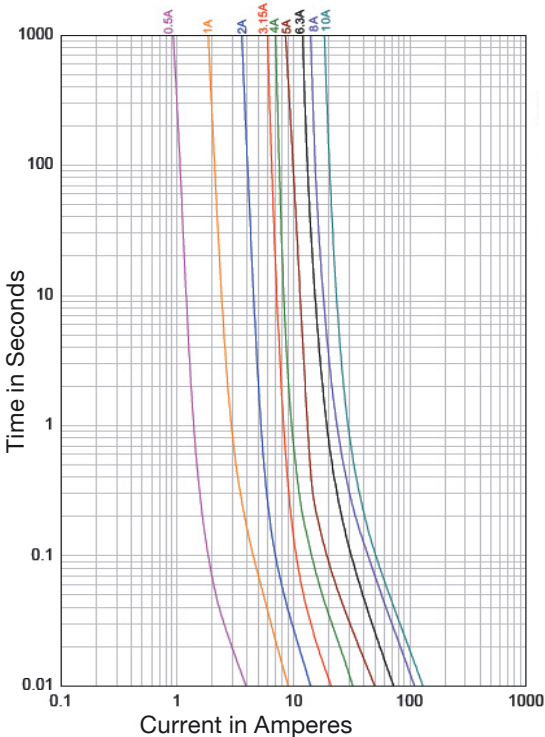

CF0521CT & CFB0521CT

Average Time Current (I-T Curves)

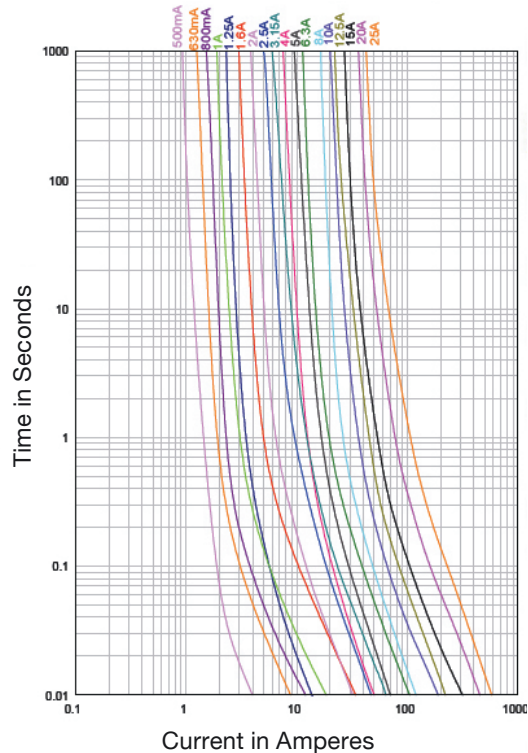

PCB
TERMINAL
BLOCKS

INTER-
CONNECTION

FUSES &
FUSE-
HOLDERS

LEDs &
INDICATORS

MINIATURE
SWITCHES

LIMIT &
SAFETY
SWITCHES

CONTROL
PRODUCTS

INTERFACE
MODULES &
SUPPORTS

RELAY
BASES

DIN RAIL
ENCLOSURES

BATTERIES

SOLAR
PANELS

TRANS-
FORMERS



+44 (0)1638 716101
info@camdenboss.com
www.camdenboss.com

We operate a constant improvement
policy, our products are subject to
change without notice.

Ver 1.2

