




## 6~24W AC-DC UK Plugtop Power Supplies

- FR4 PCB
- 100% ATE Tested
- High Reliability
- Built in OVP, OCP & SCP
- 100% smart burn-in test for 4 hours
- Level VI Efficiency Regulations Compliant
- Universal Input 90~260V AC 47~63Hz



### DIMENSIONS

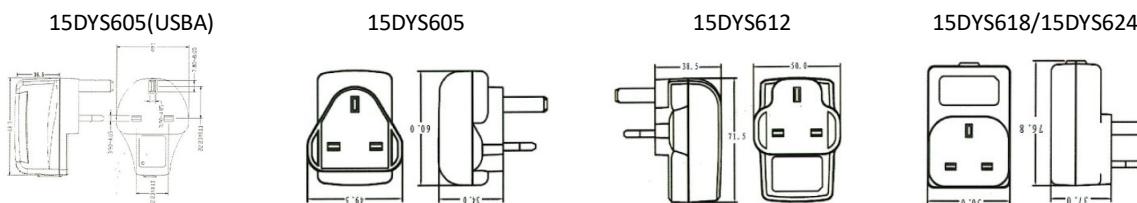

SPECIFICATIONS		15DYS605(USBA)	15DYS605	15DYS612	15DYS618	15DYS624
Input	Input Range	100~240VAC (Full Range), 50/60Hz				
	Input Current (RMS)	0.2A@90VAC 0.1A@264VAC	0.4A@90VAC 0.15A@264VAC	0.5A@90VAC 0.2A@264VAC	0.8A@90VAC 0.4A@264VAC	
Output	Voltage Range	5VDC	4~15VDC	4~24VDC		5~30VDC
	Voltage Regulation	+/- 5% At Constant Voltage Mode				
	Current Range	0.1~1.2A		0.1~2.4A	0.1~3.5A	0.1~4.0A
	Max Power	6W		12W	18W	30W
Energy Saving		NRCAN, DOE, ERP, GEMS, Efficiency Level VI				
Environmental Protection		RoHS, REACH, PAHS				
Environmental	Operating Temperature	0°C ~45°C Ambient				
	Storage Temperature	-20°C ~+80°C				
	Operating Humidity	10~90% (Non-condensing)				
	Relative Humidity	5~95% (Non-condensing)				
	MTBF	>25,000 hours at 80% load and 25°C ambient temperature				
Approvals		CE-EMC, LVD, RoHS & REACH				

VAT No. GB 771 1607 40

Registered in England No. 4063412

Weee Reg. WEE/DD0749YY



+44 (0) 845 260 3400



[enquiries@idealpower.co.uk](mailto:enquiries@idealpower.co.uk)



[idealpower.co.uk](http://idealpower.co.uk)

Ideal Power Ltd.

14 Larks Way  
Tree Beech Enterprise Park  
Gunn, Barnstaple  
Devon, EX32 7NZ  
England, UK