

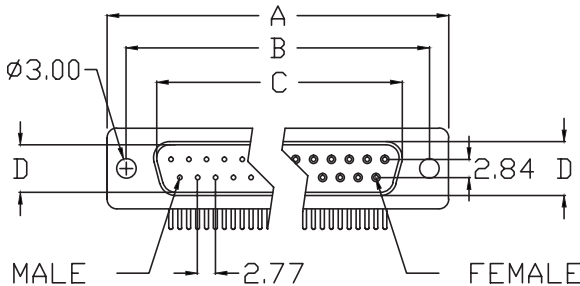



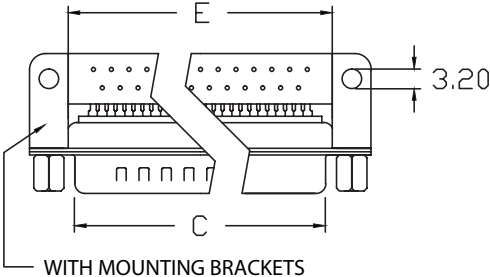


Professional D Connectors


Order code: **15-0610** 25-way Right Angle PCB Mount Plug
Order code: **15-0625** 9-way Right Angle PCB Mount Socket

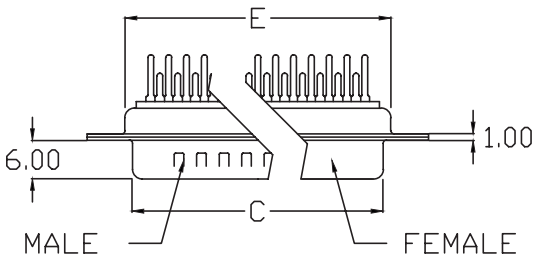

(09 PIN ~ 37 PIN)

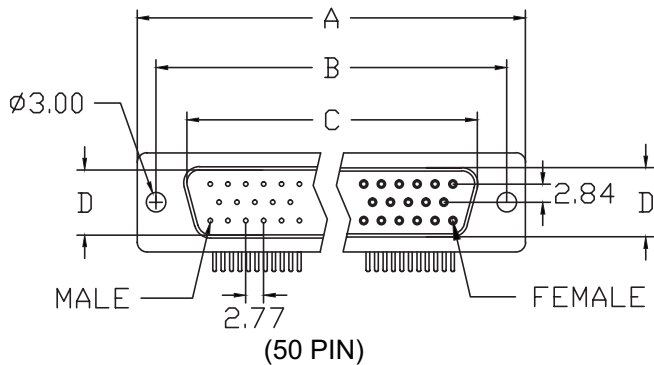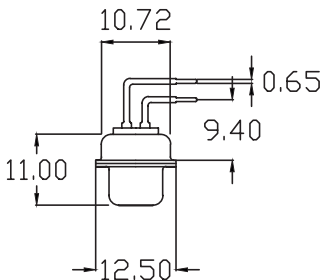

(50 PIN)

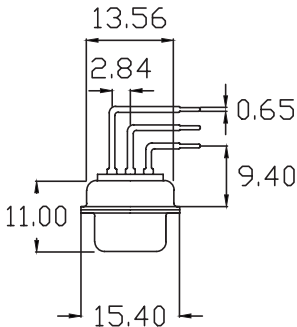

Material & Electrical:

Insulator: PBT & 30% Glass-fibre UL-94-V0
Contact: Brass
Plating: Gold plated over nickel
Current rating: 5 Amp
Dielectric strength: 1000V for one minute
Insulator resistance: 100MΩ min. at 500V DC
Temperature: -55°C ~ +105°C

Position	Plus (M)/Recept (F)	A	B	C	D	E
9	Plug (M)	30.81	24.88	16.92	8.36	19.28
	Recept (F)			16.33	7.90	
25	Plug (M)	53.04	47.04	38.96	8.36	41.30
	Recept (F)			38.38	7.90	