



10W - 800 Lumens



30W - 2400 Lumens



50W - 4000 Lumens

### Key features:

- Energy efficient LED
- Save up to 90% on electricity costs
- 50,000 hours - Lifespan
- Tough aluminium housing & tempered glass
- Slimline design
- Anti glare cover
- No heat
- 120° beam angle

Designed for quick and simple installation

**2 Ways To Connect To Mains AC Supply:**

**Directly Into Internal Terminal Block**

Or

**With Cable Provided Into A Suitable Rated Junction Box.**



800	10 Metres
2400	20 Metres
4000	30 Metres



220-240V




IP65



120° Beam

### Easy and simple installation

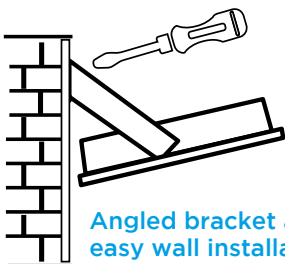

Angled bracket allows easy wall installation



Perfect for home and security related applications.

PRODUCT CODE	DIMENSIONS	WEIGHT
NSFASTSTAR10	(L)145x(W)140x(D)36mm	500g
NSFASTSTAR30	(L)200x(W)195x(D)37mm	970g
NSFASTSTAR50	(L)242x(W)235x(D)49mm	1.3KG