


Hazard Warning Lights



The PULSAR Pro is a multi-mode, rechargeable LED warning lights; designed for traffic control, signalling, hazard awareness, zone demarcations and vehicle safety. Ideal for professional applications, including the Police, Fire and Highway Services. These small but robust units are manufactured in shock resistant plastic housing, are waterproof (up to 10 metres) and virtually indestructible (withstanding most vehicle weights if crushed). Built in magnets allow attachment to vehicles or any metal surfaces.

EMERGENCY RECHARGEABLE LED HAZARD LIGHTS

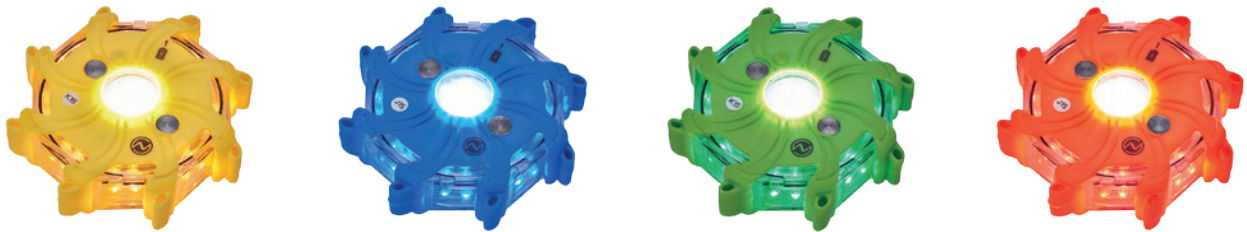

Designed for hazard awareness or signalling they are compact and robust

Pulsar Pro available in yellow, blue, green and Red

Supplied as a single unit or a set of 5



Crushproof

Up to 3 tonnes - shock resistant

Pulsar range key features

- Visible from over 1 Kilometre
- 360° Illumination
- 10 Light modes
- Operates up to 60hrs
- Waterproof up to 10m
- Designed to meet IP65 rating
- Floats in water
- White torch setting
- Magnetic back
- Rechargeable
- Working Temperature -40° to 60°C



White flood light setting


Strong magnetic back

Pulsar-Pro Rechargeable Range



Hazard Warning Lights

Single Rechargeable Pulsar

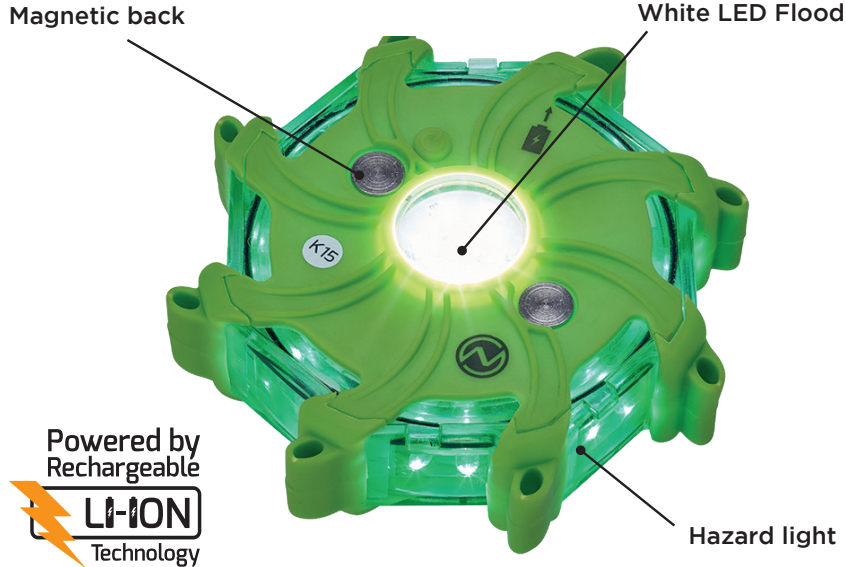

Demarcation

Single Unit - Pulsar Pro



PRODUCT CODE	COLOUR	MILLICANDELA (MDC)
NSPULSARPRO-B	Blue	6,000
NSPULSARPRO-G	Green	11,000
NSPULSARPRO-R	Red	7,000
NSPULSARPRO-Y	Yellow	7,500

Pulsar Dimensions: (D)110mx H)24mm

Supplied with:

- Charging base
- Charging cable
- Car charger

Optional Accessories:

- Cone mount
- AC Mains adaptor

Run times for light modes:

Rotate	9hrs
Quad Flash	9hrs
Single Blink	60hrs
Alternating Blinks	9hrs
SOS Rescue	14hrs
Steady on High	5hrs
Steady on Low	35hrs
2 LED Lights	28hrs
4 LED Lights	18hrs
White Torch Mode	8hrs