


Hazard Warning Lights



The PULSAR Pro is a multi-mode, rechargeable LED warning lights; designed for traffic control, signalling, hazard awareness, zone demarcations and vehicle safety. Ideal for professional applications, including the Police, Fire and Highway Services. These small but robust units are manufactured in shock resistant plastic housing, are waterproof (up to 10 metres) and virtually indestructible (withstanding most vehicle weights if crushed). Built in magnets allow attachment to vehicles or any metal surfaces.

EMERGENCY RECHARGEABLE LED HAZARD LIGHTS

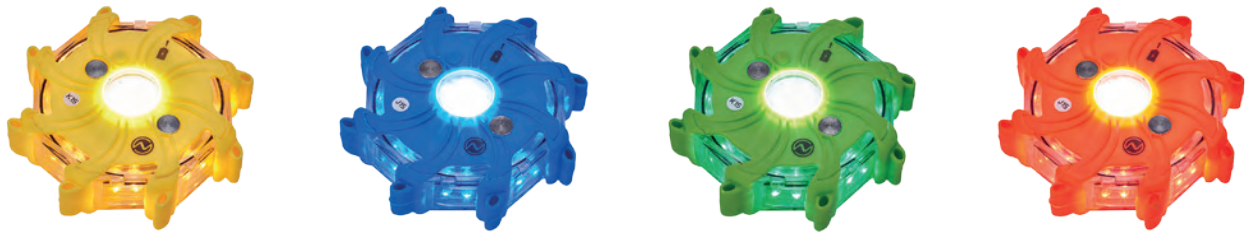

Designed for hazard awareness or signalling they are compact and robust

Pulsar Pro available in yellow, blue, green and Red

Supplied as a single unit or a set of 5



Crushproof

Up to 3 tonnes - shock resistant

Pulsar range key features

- Visible from over 1 Kilometre
- 360° Illumination
- 10 Light modes
- Operates up to 60hrs
- Waterproof up to 10m
- Designed to meet IP65 rating
- Floats in water
- White torch setting
- Magnetic back
- Rechargeable
- Working Temperature -40° to 60°C



White flood light setting


Strong magnetic back

Pulsar-Pro Rechargeable Range



Hazard Warning Lights

Single Rechargeable Pulsar

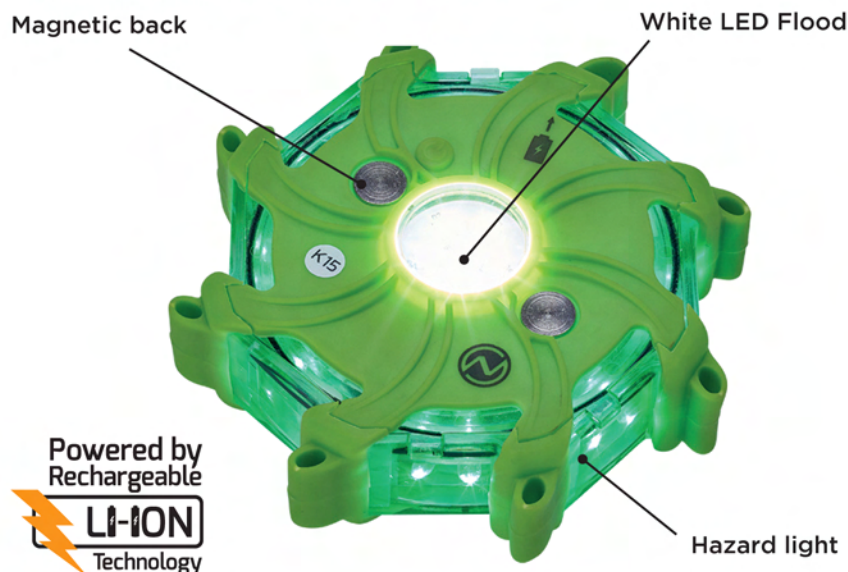


Demarcation

Run times for light modes:

Rotate	9hrs
Quad Flash	9hrs
Single Blink	60hrs
Alternating Blinks	9hrs
SOS Rescue	14hrs
Steady on High	5hrs
Steady on Low	35hrs
2 LED Lights	28hrs
4 LED Lights	18hrs
White Torch Mode	8hrs

Set of Five Rechargeable Pulsar-Pro

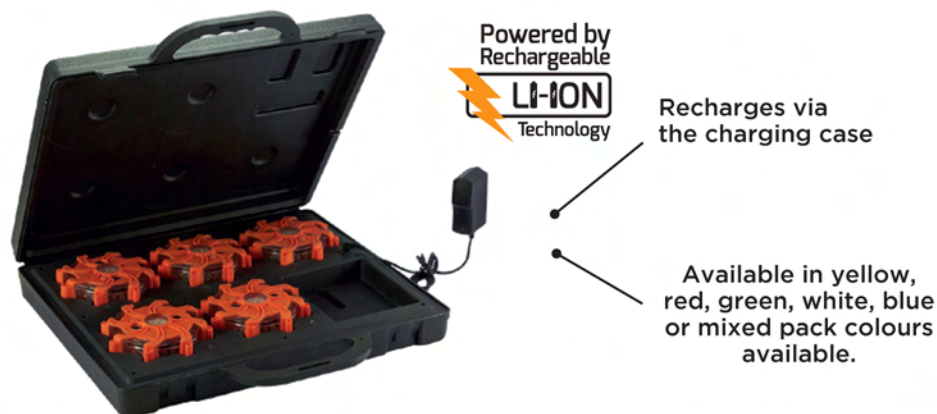

Set Of Five Pulsar Pro




PRODUCT CODE	COLOUR	MILLICANDELA (MDC)
NSPULSARPRO5-B	Blue	6,000
NSPULSARPRO5-G	Green	11,000
NSPULSARPRO5-R	Red	7,000
NSPULSARPRO5-Y	Yellow	7,500
CAT/PAD: 0111/107593		

Supplied with:

- Charging case
- AC Mains charger
- 12v Car charger

Optional Accessories:

- Cone mount

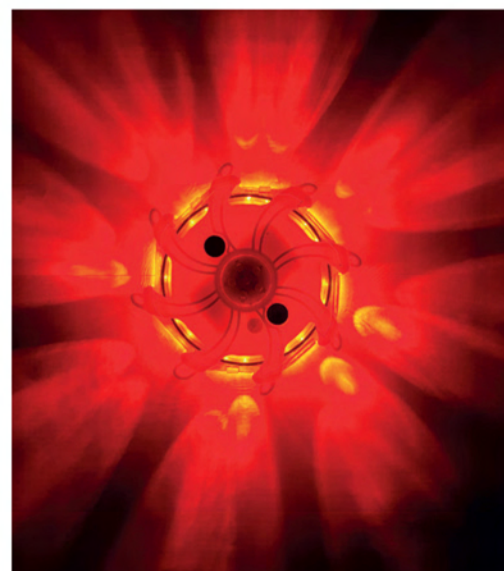

360° Light Spread visible for 1km