

## Product information


# 97 21 215 B

## Crimping Pliers

- For cutting cables, stripping wire and crimping insulated and non-insulated terminals, connectors and plug type connectors
- With threaded holes for cutting copper and brass screws threaded M 2.6 / M 3 / M 3.5 / M 4 and M 5
- Bolted joint for higher stability and even movement
- Special steel, high-strength




General	
Article No.	97 21 215 B
EAN	4003773019695
Pliers	black lacquered
Handles	with multi-component grips
weight	290 g
Dimensions	230 x 63 x 25 mm
Reach	no
RohS	no

Technical details	
	
Applications	non-insulated open plug-type connectors (plug width 6.3 mm)
Capacity in square millimetres	0.5 — 2.5 mm <sup>2</sup>
Number of crimping positions	3
AWG	20 — 13

Classification	
eCl@ss 5.1.4	21040301
ETIM 5.0	EC000168
ETIM 6.0	EC000168
proficl@ss 6.0	AAA946c003
UNSPSC 13.1	27112147

technical change and errors excepted

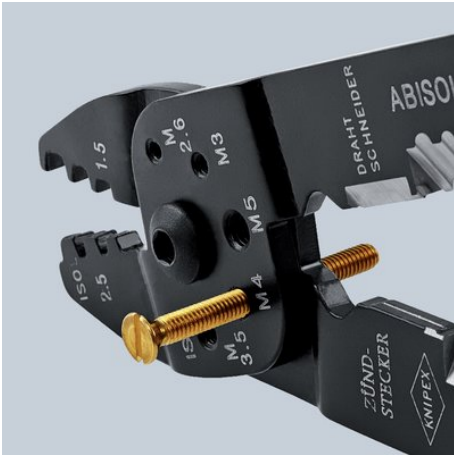

97 21 215 B



97 21 215 B



97 21 215 B



97 21 215 B