

Product information

90 20 185

KNIPEX PlastiCut®

Cutter for flexible hoses and plastic conduit pipes


- For cutting thin walled plastic pipes (conduit plastic pipes) and flexible hoses, also with fabric reinforcement, of plastic and rubber up to Ø 25 mm / 1"
- Not suitable for cutting cables
- With opening spring and locking device
- Blades: special tool steel, oil-hardened, interchangeable
- Tool body: plastic, fibreglass-reinforced



AAA

General	
Article No.	90 20 185
EAN	4003773067122
Head	chrome plated
Handles	tough fibreglass reinforced plastic handles
weight	172 g
Dimensions	185 x 70 x 25 mm
Reach	yes
RohS	no
Technical details	
Cutting capacities (diameter)	Ø 25 mm
Cutting edge length mm	Ø 25 mm
Classification	
eCl@ss 5.1.4	21040601
ETIM 5.0	EC000148
ETIM 6.0	EC000148
proficl@ss 6.0	AAB927c006
UNSPSC 13.1	23151901

technical change and errors excepted

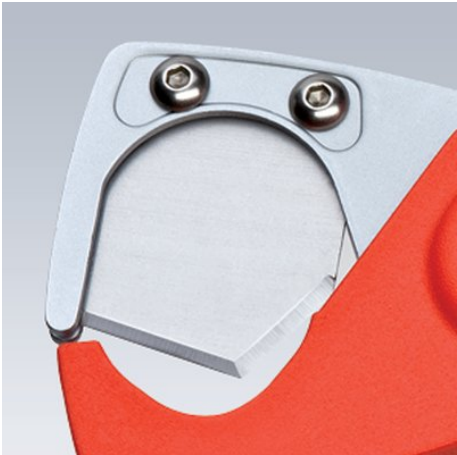

With replaceable blade

