

## Product information

**62 12 120**

### Electronics Oblique Cutting Nipper

DIN ISO 9654

- With cutting edges for soft and medium hard wire
- Without bevel, for flush cutting
- Low-friction double spring for gentle and even opening
- Sturdy, zero backlash box joint
- The polish together with a fine film of oil offer effective rust protection - no circuit faults caused by peeling chrome from plated tools
- Cutters additionally laser hardened, cutter hardness at least 56 HRC
- Ball bearing chrome steel, oil hardened




MM   $\angle 15^\circ$

#### General

Article No.	62 12 120
EAN	4003773048008
Head	polished
Handles	with multi-component grips
weight	70 g
Dimensions	120 x 67 x 17 mm
Standard	DIN ISO 9654
Reach	no
RohS	no

#### Technical details

Cutting capacities soft wire (diameter)	Ø 0.3 / 1.0 mm
Cutting capacities medium hard wire (diameter)	Ø 0.7 mm
	10 mm
	7.5 mm
Cutting edge length mm (C)	17 mm
Head width (A)	11 mm

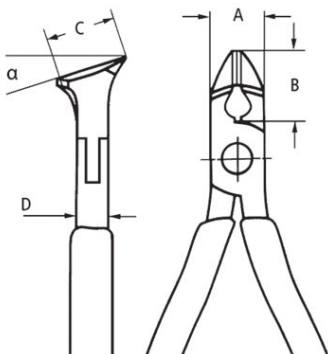

## Classification

eCl@ss 5.1.4	21040301
proficl@ss 6.0	AAA947c004

*technical change and errors excepted*

