

Product information

30 16 160

- Heavy duty and wear resisting
- Different jaw styles
- Long, trapezoidal jaws
- Chrome vanadium electric steel, forged, oil-hardened


Long Nose Pliers

DIN ISO 5745 IEC 60900 DIN EN 60900



General	
Article No.	30 16 160
EAN	4003773001904
Pliers	chrome plated
Head	chrome plated
Handles	insulated with multi-component grips, VDE-tested
weight	150 g
Dimensions	160 x 57 x 18 mm
Standard	DIN ISO 5745 DIN EN 60900 IEC 60900
Reach	no
RohS	no

Technical details	
Style	1
	9.5 mm
Tips width (W4)	3.0 mm
Tips thickness (T2)	5.0 mm
	46.5 mm
Head width (W3)	16.5 mm

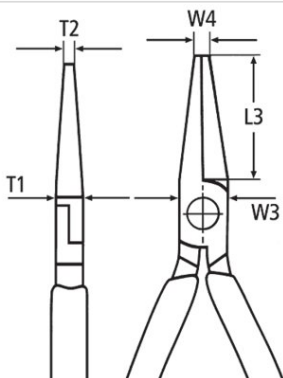



Classification	
eCl@ss 5.1.4	21040301
proficl@ss 6.0	AAA004c004
UNSPSC 13.1	27112134

technical change and errors excepted