

## Product information

# 30 36 160

- Heavy duty and wear resisting
- Different jaw styles
- Long, round jaws
- Chrome vanadium electric steel, forged, oil-hardened


## Long Nose Pliers

DIN ISO 5745 IEC 60900 DIN EN 60900



General	
Article No.	30 36 160
EAN	4003773002123
Pliers	chrome plated
Head	chrome plated
Handles	insulated with multi-component grips, VDE-tested
weight	141 g
Dimensions	160 x 57 x 18 mm
Standard	DIN ISO 5745 DIN EN 60900 IEC 60900
Reach	no
RohS	no

Technical details	
Style	3
	9.5 mm
Tips width (W4)	5.0 mm
Tips thickness (T2)	2.5 mm
	41.0 mm
Head width (W3)	16.5 mm

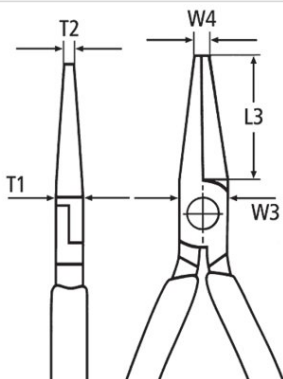



<b>Classification</b>	
eCl@ss 5.1.4	21040301
proficl@ss 6.0	AAA004c004
UNSPSC 13.1	27112134

*technical change and errors excepted*