 


Single shut off quick release couplings

238 Series



Durable construction

High flow rates, low pressure drop

Can be used with steel plugs fitted to air tools

Technical data

Operating pressure:
0 to 35 bar

Ambient temperature:
-20°C to +100°C

Air flow:
(6 bar inlet pressure)
 $C_v = 1,476$

Compatibility

Rectus 25/26, Legris 25/26

Bosch size 3

Parker PE/PEF52

Cejn 320

PCL AC71

Materials



Coupler back, body & sleeve:
nickel plated brass

Valve: brass

Spring & balls: stainless steel

Seals: Buna N

Plug: nickel plated brass

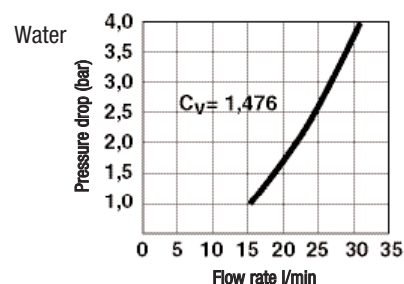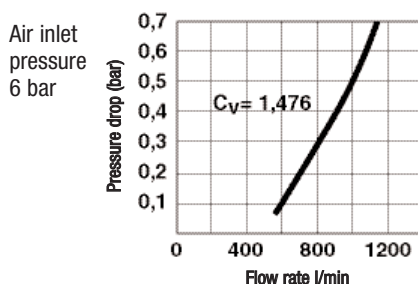

Socket - male thread

BSPP	
1/4	238210028
3/8	238210038
1/2	238210048



Plug - male thread

BSPP	
1/8	238110018
1/4	238110028
3/8	238110038
1/2	238110048



Socket - female thread

BSPP	
1/4	238220028
3/8	238220038
1/2	238220048



Plug - female thread

BSPP	
1/4	238120028
3/8	238120038
1/2	238120048



Socket - hose barb

ID Hose	
6	238230600
9	238230900
13	238231300



Plug - hose barb

ID Hose	
6	238130600
9	238130900
13	238131300