

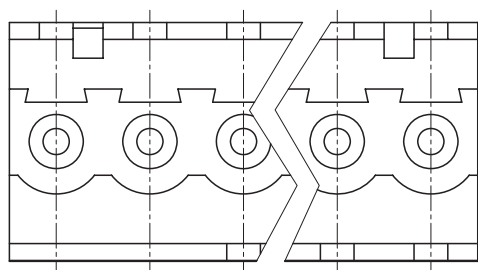


5mm Female Pluggable Vertical 15A Terminal Blocks

Pitch: 5mm
 Rated voltage/current: 300V/15A
 Operating temperature: -40°C to +105°C
 Withstand voltage: 2500V AC for 60s
 Insulation resistance: 500MΩ at 500V DC
 Wire range: 28 to 12AWG 2.5mm²
 Max. torque value: 0.5 Nm

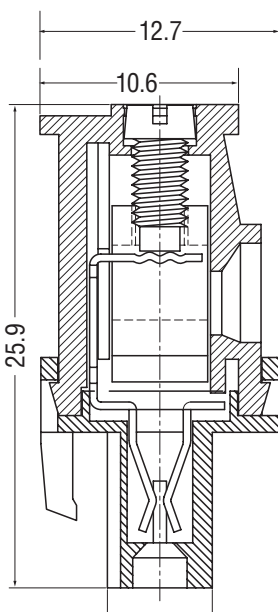

Housing colour: Green
 Screw: Zinc-plated steel (A3)
 Wire cage: Nickel-plated brass
 Contact: Phosphor bronze
 Wire stripping length: 6 to 7mm
 Wave soldering: 260°C for 5s
 Hand soldering: 350°C for 10s

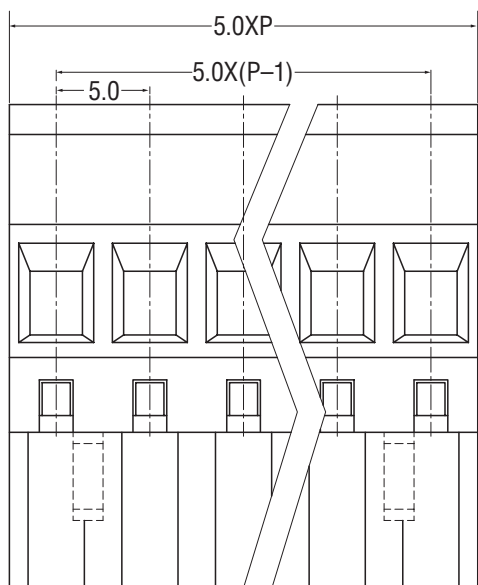

Order code	Poles
21-5350	2
21-5351	3
21-5352	4

