


7.5mm Female Pluggable Horizontal 15A Terminal Blocks

Pitch: 7.5mm
 Rated voltage/current: 300V/15A
 Operation temperatures: -40°C to +105°C
 Withstand voltage: 2500V AC for 60s
 Insulation resistance: 500MΩ at 500V DC
 Wire range: 28 to 12AWG 2.5mm²
 Max. torque value: 0.4 Nm

Housing colour: Green
 Screw: Zinc-plated steel (A3)
 Wire cage: Nickel-plated brass
 Contact: Phosphor bronze
 Wire stripping length: 6 to 7mm
 Wave soldering: 260°C for 5s
 Hand soldering: 350°C for 10s

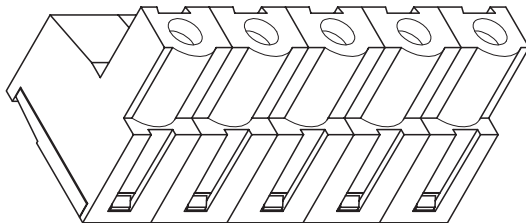

Order code	Poles
21-5370	2
21-5371	3
21-5372	4
21-5373	5
21-5374	6
21-5375	8
21-5376	10
21-5377	12

