
 
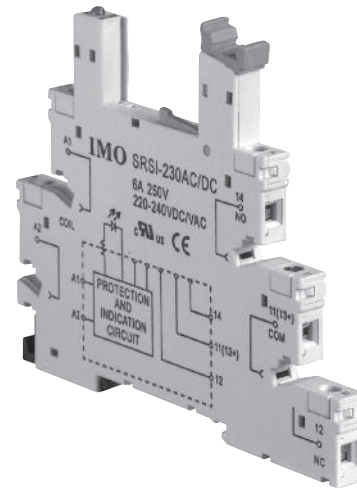



Characteristics

Ambient temperature	-40 to 70 °C
Rated voltage	250VAC
Rated current	6A (Per pole)
Insulation voltage (min.)	5000VAC
Protection degree	IP20
Socket material	PA66+GF V0 (UL)
Contacts spring material	QSn6.5-0.1
Retainer	No
Modules (on request)	Self-contained
Terminal torque	0.6Nm
Wire strip length	7mm

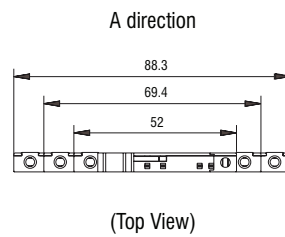

Outline dimensions

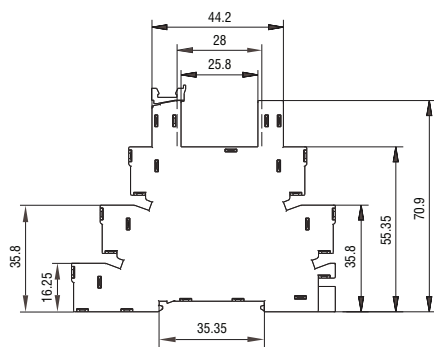

Socket/relay compatibility

Socket P/N	Input voltage	Relay coil voltage
SRSI-24AC/DC	6 to 24VDC/VAC	6 to 24VDC
SRSI-60AC/DC	48 to 60VDC/VAC	48 to 60VDC
SRSI-110AC/DC	110 to 125VDC/VAC	60VDC
SRSI-230AC/DC	220 to 240VDC/VAC	60VDC
SRSI-24DC*	5 to 24 DC Only	5 to 24VDC

*Note: Input voltage polarity required.

SRSI- CC20 Busbar available in 20 way

