



1m and 5m Addressable RGB LED Strip

Order code **60-8811 1m strip** 60 pieces per Metre


MPN: TRU60PCS1M

Order code **60-8813 5m strip** 60 pieces per Metre


MPN: TRU60PCS5M

Product Parameters

Working voltage:	5V DC
Working current:	3.6A/metre
Cable length:	200mm AWG22#
Working temperature:	-40°C to 60°C
Packing:	1 metre or 5 metre/roll
LED number:	60pcs/metre
Viewing angle:	120°

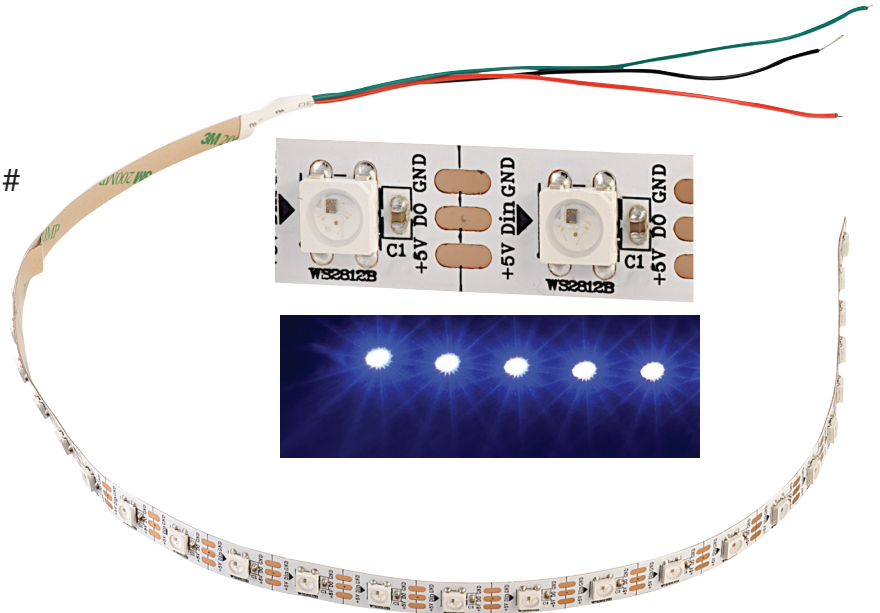

Product size:

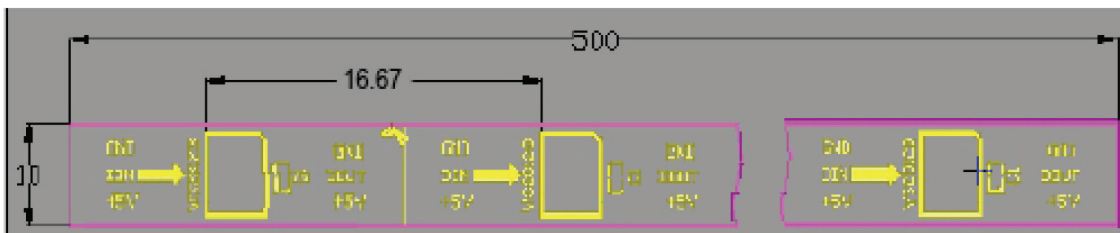

Distribution Wiring Diagram

