


## Data Sheet

### Push button switch

Version 08/22

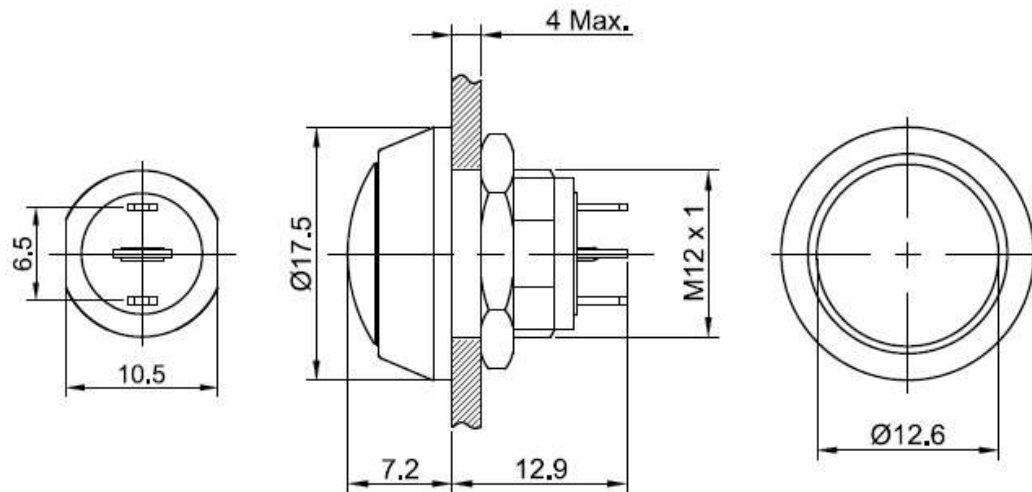

4MAX: means the panel thickness, the max thickness for the panel no more than 4mm.

### Specification

|                                         |                          |
|-----------------------------------------|--------------------------|
| Mounting diameter .....                 | 13mm                     |
| Head shape .....                        | Domed head               |
| Operation type .....                    | Momentary                |
| Contact structure .....                 | 1NO                      |
| Switch rating .....                     | 2 A/48 VDC               |
| Terminal .....                          | Soldering Pins           |
| Body material .....                     | Zn-Al alloy              |
| Operating and storage temperature ..... | -25 to +55 °C            |
| Operating and storage humidity .....    | 45 to 85 % RH            |
| Base material .....                     | PA                       |
| IP rating .....                         | IP65                     |
| Mechanical lifetime .....               | 1,000,000 cycles         |
| Electrical lifetime .....               | 200,000 cycles           |
| Dielectric strength .....               | 1500V, AC 50HZ, 1 minute |
| Insulation resistance .....             | ≥ 100MΩ (500VDC)         |

| Item no. | Head color |
|----------|------------|
| 2522750  | Red        |
| 2522751  | Green      |
| 2522752  | Blue       |
| 2522753  | Black      |