


### Specifications



Pitch:	2.00mm
Type:	Kinked Pin
Poles:	2 to 12
Rated Voltage:	100V
Rated Current:	2A
Operational Temperature:	-25°C to +85°C
Withstand Voltage:	800V AC for 60s
Insulation Resistance:	1000MΩ
Contact Resistance:	20MΩ
Recommended PC Board Thickness:	1.6mm
Housing Material:	Nylon 66

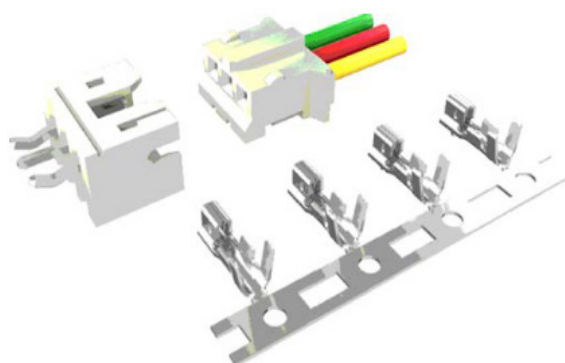

Order Code	Poles	$A = (N+1) * 2.00$	$B = (N-1) * 2.00 \pm 0.25$
65-6609	2	6.00	2.00
65-6618	3	8.00	4.00
65-6619	4	10.00	6.00
65-6620	5	12.00	8.00
65-6621	6	14.00	10.00
65-6622	8	18.00	14.00
65-6623	10	22.00	18.00
65-6624	12	26.00	22.00

**Note:** N = No. of contact

### Male Vertical Type

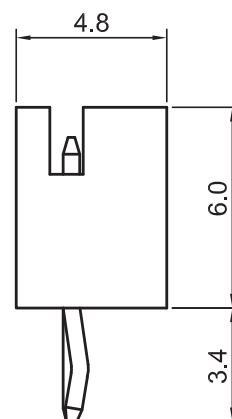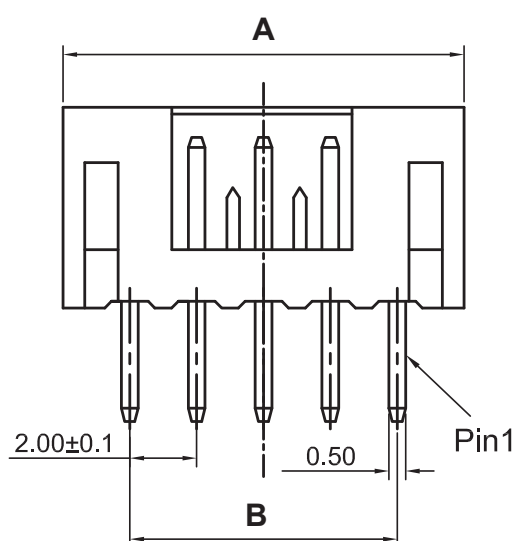

Kinked Pin

For further information on pricing, delivery, and long-term stock agreements please get in touch with your local business development contact. Telephone our main office on **01206 751166** or email **Sales@Rapidoonline.com**.

The information contained in this datasheet is subject to change without notice and replaces all data sheets previously supplied.

