


XH Type Female Housing & Contact

2.5mm Pitch

Specifications


Pitch:	2.5mm
Type:	Female Housing/Contact
Poles:	2 to 12
Rated Voltage:	250V
Rated Current:	3A
Operational Temperature:	-25°C to +85°C
Withstand Voltage:	500V AC for 60s
Insulation Resistance:	1000MΩ
Wire Range:	AWG#28~#22
Contact Resistance:	30MΩ
Contact Plating:	Tin
Housing Material:	Nylon 66
Contact Material:	Phospor Bronze

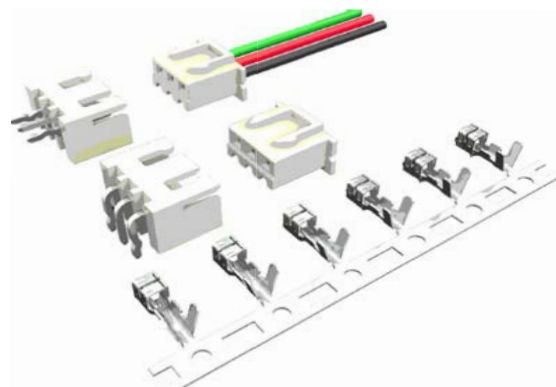


Order Code		Poles	$A = N \times 2.5 + 2.3$	$B = (N-1) \times 2.5$	$C = N \times 2.5 + 0.7$
65-6641	Contact	-	-	-	-
65-6642	Housing	2	7.3	2.5	5.7
65-6643	Housing	3	9.8	5.0	8.2
65-6644	Housing	4	12.3	7.5	10.7
65-6645	Housing	5	14.8	10.0	13.2
65-6646	Housing	6	17.3	12.5	15.7
65-6647	Housing	8	22.3	17.5	20.7
65-6648	Housing	10	27.3	22.5	25.7
65-6649	Housing	12	32.3	27.5	30.7

Note: N = No. of contact

Female Housing

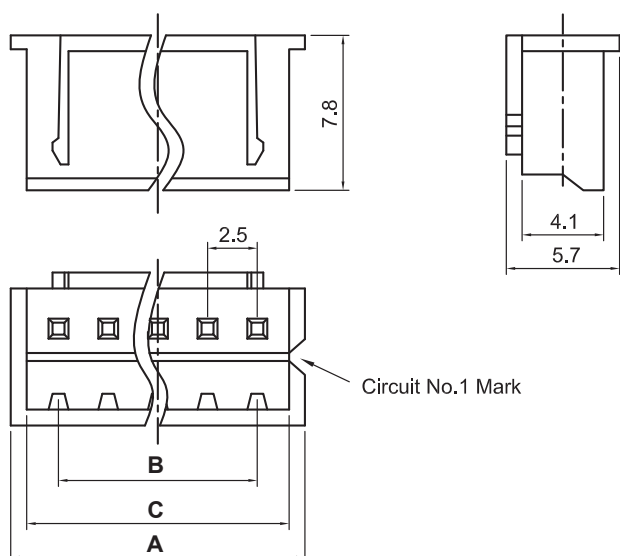

Female Contact

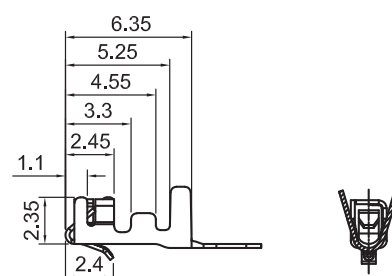

For further information on pricing, delivery, and long-term stock agreements please get in touch with your local business development contact. Telephone our main office on **01206 751166** or email **Sales@Rapidonline.com**.

The information contained in this datasheet is subject to change without notice and replaces all data sheets previously supplied.

