


Specifications


Pitch:	2.5mm
Type:	Straight Pin
Poles:	2 to 12
Rated Voltage:	250V
Rated Current:	3A
Operational Temperature:	-25°C to +85°C
Withstand Voltage:	500V AC for 60s
Insulation Resistance:	1000MΩ
Contact Resistance:	30MΩ
Recommended PC Board Thickness:	1.6mm
Housing Material:	Nylon 66

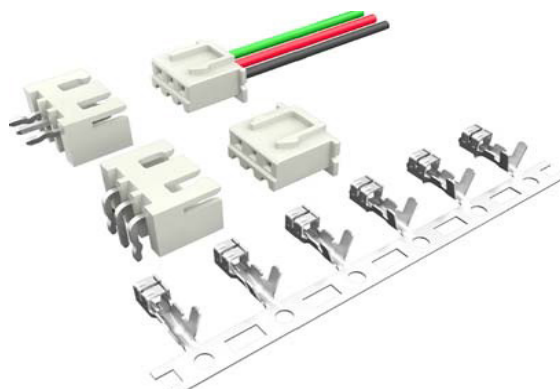



Order Code	Poles	$A = (N+1) * 2.5$	$B = (N-1) * 2.5$
65-6771	2	7.5	2.5
65-6772	3	10.0	5.0
65-6773	4	12.5	7.5
65-6774	5	15.0	10.0
65-6775	6	17.5	12.5
65-6776	8	22.5	17.5
65-6777	10	27.5	22.5
65-6778	12	32.5	27.5

Note: N = No. of contact

Male Right Angle

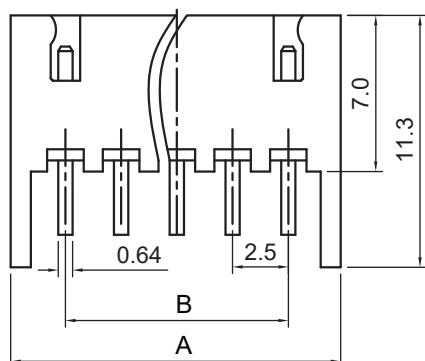

Straight Pin

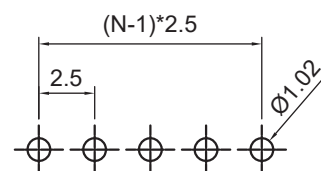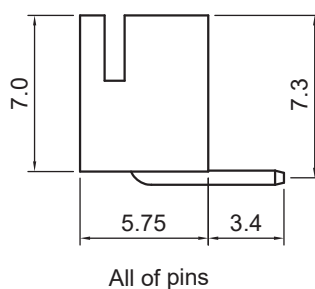

Recommend PCB layout
(Tolerance: ±0.05)

