



## Specifications

Pitch:	3.96mm
Type:	Vertical Header
Poles:	2 to 12
Rated Voltage:	250V
Rated Current:	7A
Operational Temperature:	-25°C to +85°C
Withstand Voltage:	1000V AC for 60s
Insulation Resistance:	1000MΩ
Contact Resistance:	30MΩ
Recommended PC Board Thickness:	1.6mm
Housing Material:	Nylon 66

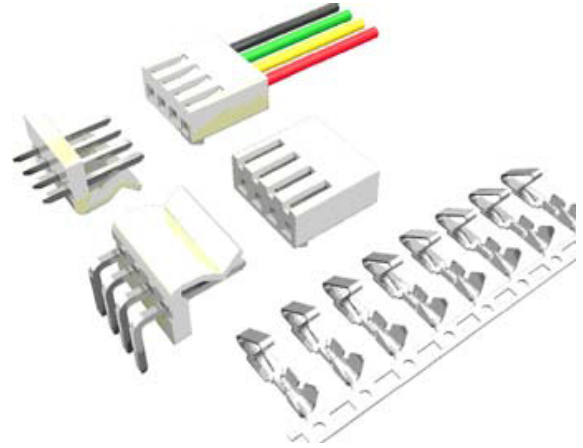

Order Code	Poles	A = N*3.96	B = (N-1)*3.96	C
65-6718	2	7.92	3.96	3.5
65-6719	3	11.88	7.92	3.5
65-6720	4	15.84	11.88	3.5
65-6721	5	19.08	15.84	3.5
65-6722	6	23.76	19.08	3.5
65-6723	8	31.68	27.72	3.5
65-6724	10	39.60	35.64	3.5
65-6725	12	47.52	43.56	3.5

## Male V/T TYPE

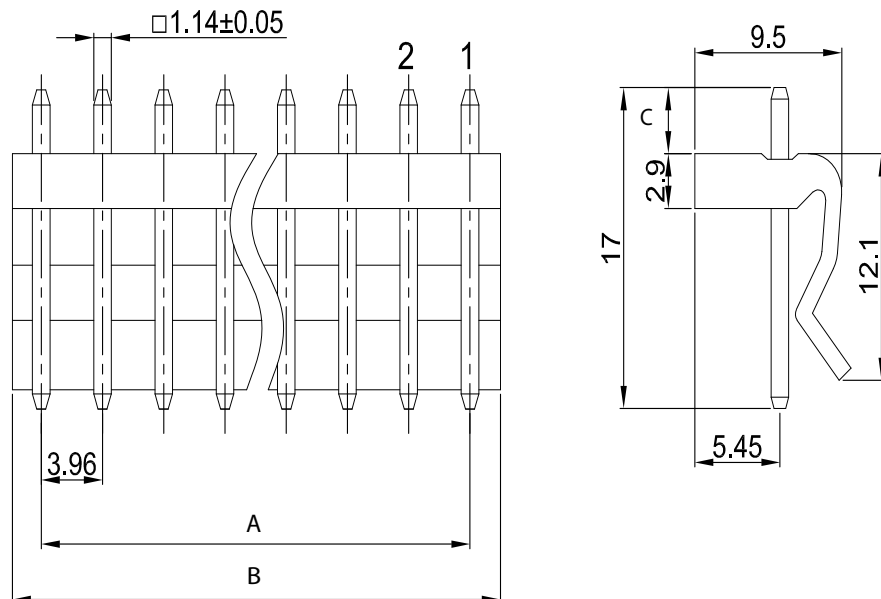

For further information on pricing, delivery, and long-term stock agreements please get in touch with your local business development contact. Telephone our main office on **01206 751166** or email [Sales@Rapidonline.com](mailto:Sales@Rapidonline.com).

The information contained in this datasheet is subject to change without notice and replaces all data sheets previously supplied.

