



## Specifications

Pitch:	3.96mm
Type:	R/A Header
Poles:	2 to 12
Rated Voltage:	250V
Rated Current:	7A
Operational Temperature:	-25°C to +85°C
Withstand Voltage:	1000V AC for 60s
Insulation Resistance:	1000MΩ
Contact Resistance:	30MΩ
Recommended PC Board Thickness:	1.6mm
Housing Material:	Nylon 66

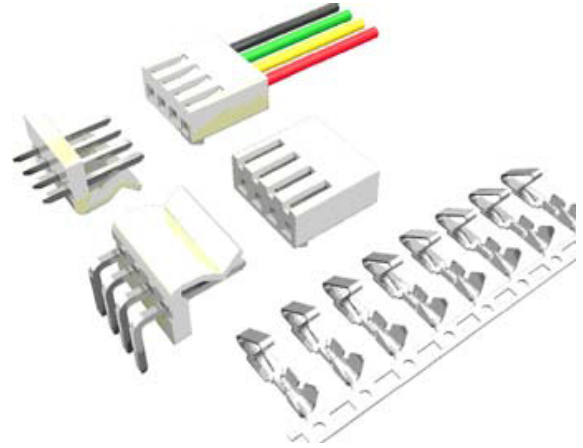

Order Code	Poles	A = N*3.96	B = (N-1)*3.96	C
65-6726	2	7.92	3.96	3.6
65-6727	3	11.88	7.92	3.6
65-6728	4	15.84	11.88	3.6
65-6729	5	19.08	15.84	3.6
65-6730	6	23.76	19.08	3.6
65-6731	8	31.68	27.72	3.6
65-6732	10	39.60	35.64	3.6
65-6733	12	47.52	43.56	3.6

### Male Right Angle

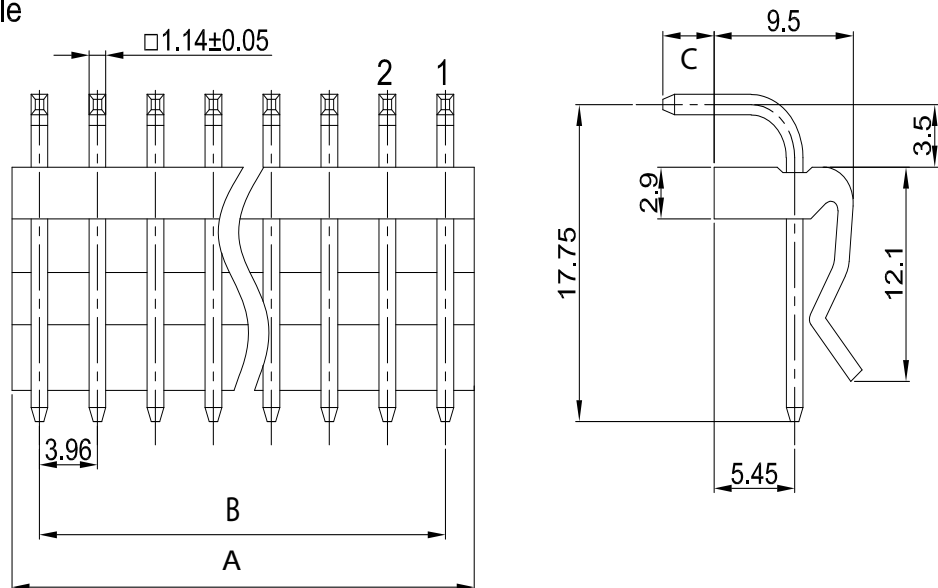

For further information on pricing, delivery, and long-term stock agreements please get in touch with your local business development contact. Telephone our main office on **01206 751166** or email [Sales@Rapidonline.com](mailto:Sales@Rapidonline.com).

The information contained in this datasheet is subject to change without notice and replaces all data sheets previously supplied.

