




Specifications

Pitch:	3.96m
Type:	Vertical Header
Poles:	2 to 12
Rated Current:	7A
Operational Temperature:	-25°C to +85°C
Withstand Voltage:	1000V AC for 60s
Insulation Resistance:	1000MΩ
Contact Resistance:	30MΩ
Recommended PC Board Thickness:	1.6mm
Housing Material:	Nylon 66

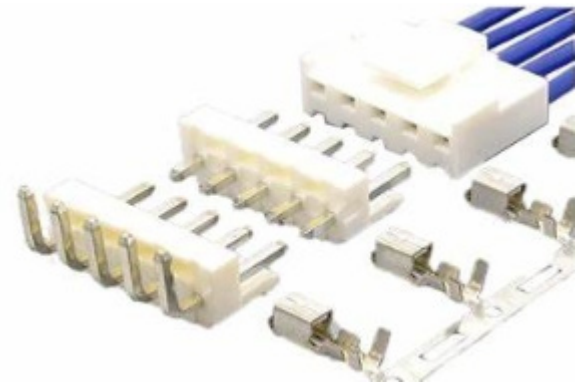

Order Code	Poles	A = N*3.96	B = (N-1)*3.96	C
65-6743	2	7.92	3.96	3.6
65-6744	3	11.88	7.92	3.6
65-6745	4	15.84	11.88	3.6
65-6746	5	19.08	20.32	3.6
65-6747	6	23.76	25.04	3.6
65-6748	8	31.68	30-48	3.6
65-6749	10	39.60	35.56	3.6
65-6750	12	47.52	40.64	3.6

V/T Type

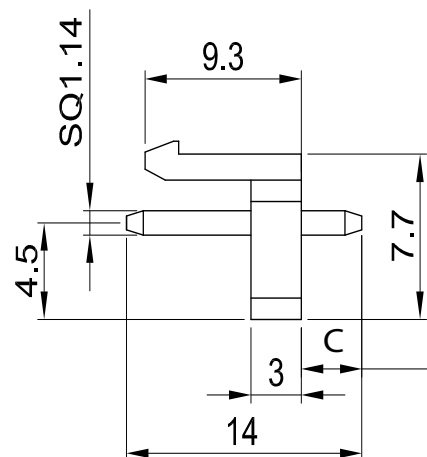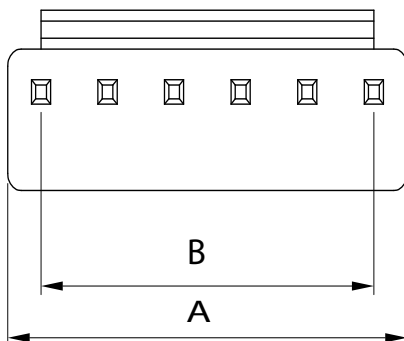

For further information on pricing, delivery, and long-term stock agreements please get in touch with your local business development contact. Telephone our main office on **01206 751166** or email Sales@Rapidonline.com.

The information contained in this datasheet is subject to change without notice and replaces all data sheets previously supplied.

