


Header 5.08mm Pitch



Specifications

Pitch:	5.08mm
Type:	Vertical Header
Poles:	2 to 12
Rated Voltage:	250V
Rated Current:	7A
Operational Temperature:	-25°C to +85°C
Withstand Voltage:	1500V AC for 60s
Insulation Resistance:	1000MΩ
Contact Resistance:	30MΩ
Recommended PC Board Thickness:	1.6mm
Housing Material:	Nylon 66

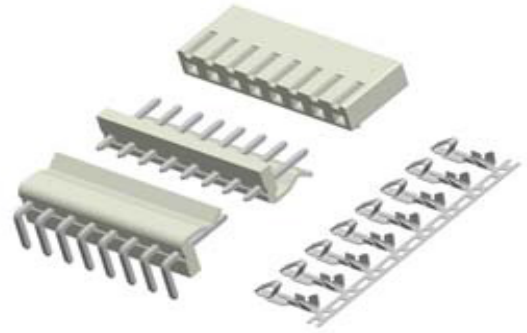

Order Code	Poles	A = N*5.08	B = (N-1)*5.08	C	D
65-6768	2	10.16	5.08	3.7	3.5
65-6769	3	15.24	10.16	3.7	3.5
65-6770	4	20.32	15.24	3.7	3.5
65-6771	5	25.04	20.32	3.7	3.5
65-6772	6	30.48	25.04	3.7	3.5
65-6773	8	35.56	30.48	3.7	3.5
65-6774	10	40.64	35.56	3.7	3.5
65-6775	12	45.72	40.64	3.7	3.5

Male V/T Type

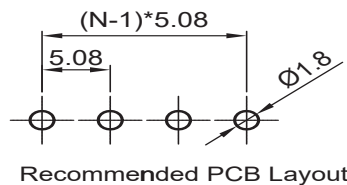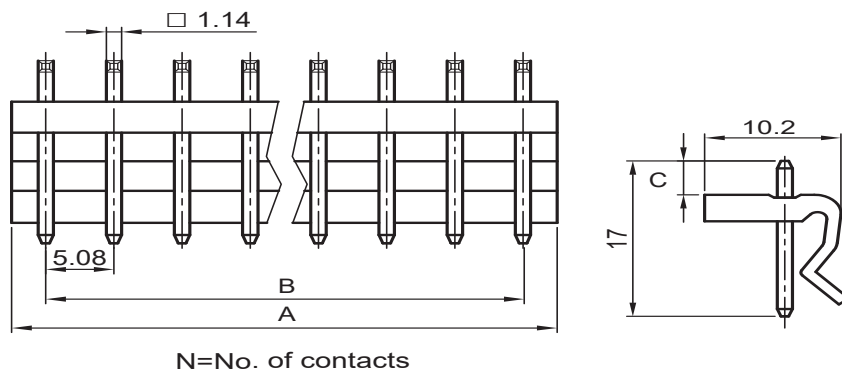

For further information on pricing, delivery, and long-term stock agreements please get in touch with your local business development contact. Telephone our main office on **01206 751166** or email **Sales@Rapidoonline.com**.

The information contained in this datasheet is subject to change without notice and replaces all data sheets previously supplied.

