


## Description:

This high-grade PVC sleeving has a thin wall that makes it ideal for insulating wire in areas where space is at a premium. Available in 5m or 100m lengths.

## Specification:

|                        |                                  |
|------------------------|----------------------------------|
| Material:              | PVC                              |
| Operating temperature: | -20°C to +80°C                   |
| Insulation resistance: | 1010 Ohm/cm                      |
| Elongation at break:   | 220%                             |
| Hardness:              | BSS20-30                         |
| Flammability:          | Self-extinguishing in 30 seconds |
| Specification:         | BS 2848/3/85T RoHS compliant     |

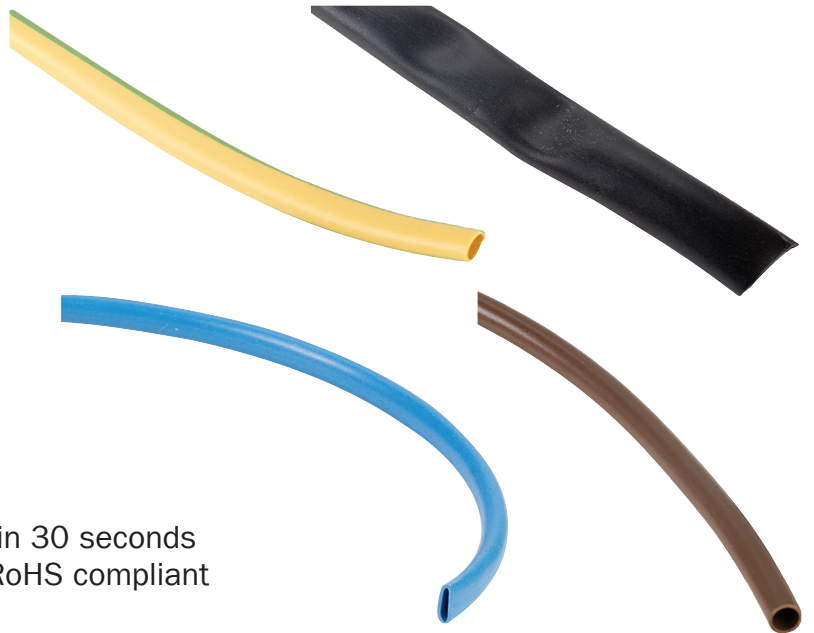

| Order code | Reel size (m) | Colour       | Internal diameter (mm) | For cable size (mm <sup>2</sup> ) |
|------------|---------------|--------------|------------------------|-----------------------------------|
| 03-1700    | 5             | Green/Yellow | 3                      | 0.5-0.75                          |
| 03-1702    | 5             | Black        | 3                      | 0.5-0.75                          |
| 03-1701    | 5             | Blue         | 3                      | 0.5-0.75                          |
| 03-1703    | 5             | Brown        | 3                      | 0.5-0.75                          |
| 03-1716    | 100           | Green/Yellow | 3                      | 0.5-0.75                          |
| 03-1718    | 100           | Black        | 3                      | 0.5-0.75                          |
| 03-1705    | 100           | Blue         | 3                      | 0.5-0.75                          |
| 03-1730    | 5             | Green/Yellow | 6                      | 6.0                               |
| 03-1732    | 5             | Black        | 6                      | 6.0                               |
| 03-1707    | 5             | Blue         | 6                      | 6.0                               |
| 03-1708    | 5             | Brown        | 6                      | 6.0                               |
| 03-1738    | 100           | Black        | 6                      | 6.0                               |
| 03-1744    | 5             | Black        | 8                      | 10.0                              |
| 03-1750    | 100           | Black        | 8                      | 10.0                              |
| 03-1717    | 100           | Blue         | 8                      | 10.0                              |
| 03-1719    | 100           | Brown        | 8                      | 10.0                              |
| 03-1756    | 5             | Black        | 10                     | 16.0-25.0                         |
| 03-1762    | 100           | Black        | 10                     | 16.0-25.0                         |