




Specifications:

Current Rating: 2V @12V DC
 Dielectric withstanding voltage: 500 V(ac) for 1 minute.
 Contact resistance: 30 mΩ max.
 Insulation resistance: 1000 mΩ min at 500V
 Total mating force: 6.0 Kgf max.
 Total unmating force: 0.5 Kgf min.
 Temperature range: -55°C~+105°C

Order code	No. of ways
20-0655	4
20-0665	6
22-0675	8

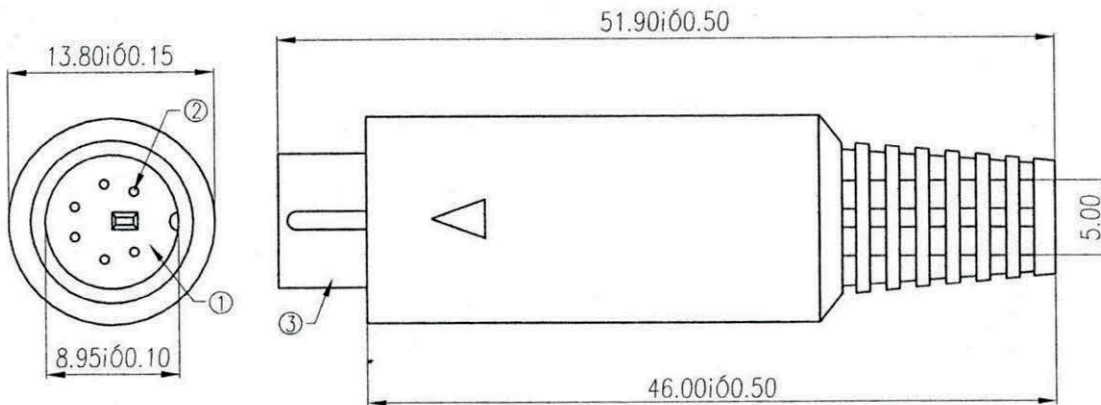

NO.OF CONTACT	3	4	5	6	7	8
PART NO.	MD-3PL	MD-4PL	MD-5PL	MD-6PL	MD-7PL	MD-8PL
POSTTION						

No.	Description	Material	Thickness	Finish
1	Housing	PBT		Black
2	Contact	Brass	T=0.60mm	Silver plated
3	Shell	Steel	T=0.40mm	80μ" Nickel plated