

PCB TERMINAL BLOCKS

5mm Pitch Low Profile 45° Rising Clamp Terminal Blocks

PCB
TERMINAL
BLOCKS

INTER-
CONNECTION

FUSES &
FUSE-
HOLDERS

LEDs &
INDICATORS

MINIATURE
SWITCHES

LIMIT &
SAFETY
SWITCHES

CONTROL
PRODUCTS

INTERFACE
MODULES &
SUPPORTS


RELAY
BASES

DIN RAIL
ENCLOSURES

BATTERIES

SOLAR
PANELS

TRANS-
FORMERS

- 2 & 3 pole interlocking
- 4-12 pole pre-assembled
- 45° mounting
- Moulded in grey UL94-V0 flame retardant PA
- Professional rising clamp terminals
- 0.2-4.0mm² (30-12AWG) solid cable
- 0.2-2.5mm² (30-12AWG) stranded cable
- Captive screw
-  approved


CTB3000



TYPE NO.	POLES	LENGTH
CTB3000/2	2	10mm
CTB3000/3	3	15mm
CTB3000/4	4	20mm
CTB3000/5	5	25mm
CTB3000/6	6	30mm
CTB3000/7	7	35mm
CTB3000/8	8	40mm
CTB3000/9	9	45mm
CTB3000/10	10	50mm
CTB3000/11	11	55mm
CTB3000/12	12	60mm

SPECIFICATION

Rating	24A/160V
	UL=16A/300V, VDE&IMQ=24A/130V
Dielectric strength	≥1.25kV
Impulse withstand voltage	2.5kV
Working temperature	110°C
Moulding	UL94-V0 flame retardant PA
Pin/terminal	Tinned, nickel plated brass
Rising clamp	Tinned, nickel plated brass
Screw/torque	M3 steel zinc plated, 0.5Nm
Recommended PCB hole size	ø1.3mm

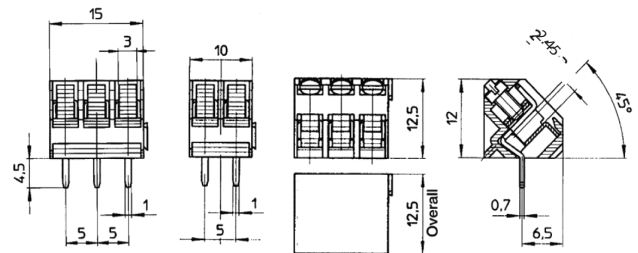

CAMDENBOSS

We operate a constant improvement policy, our products are subject to change without notice.

Ver 1.1

+44 (0)1638 716101
info@camdenboss.com
www.camdenboss.com



FM 28614 EMS 613558