

**Re an**<sup>®</sup>

A PRODUCT OF WERFO SWITZERLAND

**WERFO AG**

9469 Haag, Switzerland

Phone +41/81/772 20 00

Fax +41/81/772 20 01


info@werfo.ch

www.rean.com



# Revan<sup>®</sup> Control Knobs

A PRODUCT OF WERFO SWITZERLAND

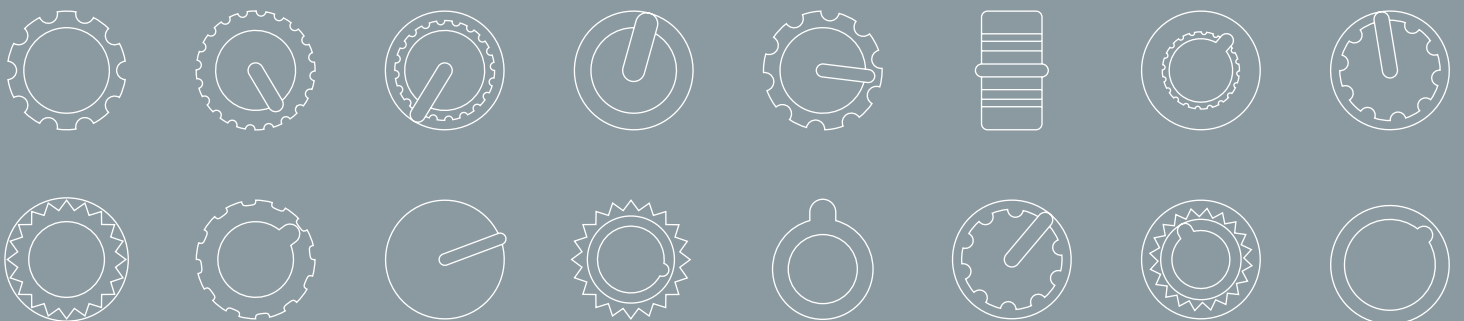

## Welcome to WERFO

Valued customer and business partner

After the successful integration of the Rean Production into Werfo Ltd., we are happy to present to you our first catalogue of Re'an Control Knobs.

Werfo Ltd., with headquarters in Switzerland, was established in 1970 and has the reputation of a very successful supplier in the Plastic Molding Industry.

Thanks to modern machinery and technology, combined with very well trained engineering and operating staff, we are capable of developing, designing and manufacturing Injection Molds and Plastic Products of the highest quality. It is a matter of course for us that we have been certified for ISO 9001 : 2000 and ISO 14644-1.

As our customer you take center stage. The ultimate goal for Werfo Ltd. is to constantly meet your wishes and requirements in terms of quality and deadlines.

Because of our longstanding cooperative partnership with the Neutrik-Group, we are able to supply the market principally through its worldwide distribution network. The close customer relationships cultivated by Neutrik for over 25 years are very important to us.

We want to continue this successful philosophy, constantly offering you the best possible service. As our contribution to your success.

Yours sincerely,



Eugen Längle  
CEO WERFO Ltd., Switzerland

# Table of Contents

---

## Flexi-Fit Control Knobs / Encoder

Page 4



---

## Push-Fit Control Knobs

Page 5 - 7



---

## Dual-Concentric Knobs

Page 8



---

## Collet Knobs

Page 9



---

## Caps

Page 10 - 11



---

## Sliders

Page 12



---

## Switch Buttons

Page 13



---

## Options Key

Page 14

---

# Flexi-Fit Control Knobs / Encoder


The newest series of one piece push on knobs is the Flexi-Fit series which features a flexible insert that allows the knob to be used on either a D flat or 6mm spline shaft. The Flexi-Fit series is the first of its kind to adapt to any orientation. This unique feature allows for versatility and becomes extremely cost effective. Should the application change because of shaft shape or orientation there's no need to buy new knobs! The question of a more tactile feel is addressed by offering the Flexi-Fit series in either hard or soft plastic. These knobs are one piece. The knobs are available in either black or gray with white lines and colored caps. The knobs are available in either black or gray with white lines and colored caps.




|  | Surface Material | Color                                     | Fitting | Orientation |   |   |
|--|------------------|---|---------|-------------|---|---|
| <b>F311</b><br>Flexi-Fit 11mm, flexible insert included. With white line | H, S             | body<br>0, 8<br>line<br>9<br>cap<br>1 - 9 | F       | -           |    |    |
| <b>F313</b><br>Flexi-Fit 13mm, flexible insert included. With white line | H, S             | body<br>0, 8<br>line<br>9<br>cap<br>1 - 9 | F       | -           |   |   |
| <b>F317</b><br>Flexi-Fit 17mm, flexible insert included. With white line | H, S             | body<br>0, 8<br>line<br>9<br>cap<br>1 - 9 | F       | -           |  |  |
| <b>F411</b><br>Flexi-Fit 11mm, flexible insert included.                 | H, S             | body<br>0, 8<br>line<br>-<br>cap<br>1 - 9 | F       | -           |  |  |

## Flexi-Fit Insert

Knobs accept one insert that will fit on either a 'D' shaft or a spline shaft. The insert slides into the knob so that the knob can be pushed onto either type shaft.

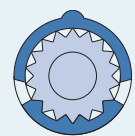

6mm Spline Fit

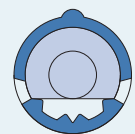

6mm Flat Fit

# Push-Fit Control Knobs - One Piece

Looking for something a little different for your application? Need a knob where you don't have to order caps separately? Then look at the REAN Push-Fit control knobs. Available in two or three colors with marker lines to fit either D flat or 6mm spline shafts. The push-fit series will address a wide variety of applications and will enhance the aesthetics of any piece of equipment.




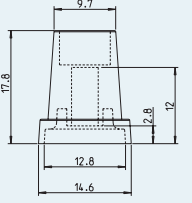

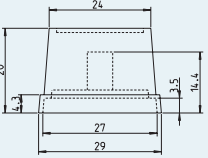

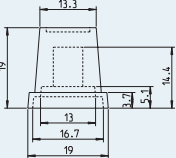

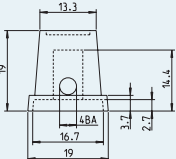

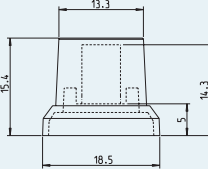
|   | Surface Material | Color   | Fitting     | Orientation |  |  |
|---|------------------|---|-------------|-------------|--|--|
| <p><b>P300</b></p> <p>Stylish three color control knob in hard or soft-touch plastics with a raised solid marker line</p>   | H, S             | <b>body</b><br>0, 8<br><b>line</b><br>0, 2, 8, 9<br><b>cap</b><br>0 - 9 | D6, S6      | N, S, W, E  |  |  |
| <p><b>P400</b></p> <p>A slim two color soft-touch knob for use in densely populated control surfaces</p>                    | S                | <b>body</b><br>0, 8<br><b>line</b><br>0 - 9<br><b>cap</b><br>-          | D6, S6      | N, S, W, E  |  |  |
| <p><b>P570</b></p> <p>Low-profile, two color control knob with integral nut cover</p>                                       | H                | <b>body</b><br>0, 8<br><b>line</b><br>0 - 9<br><b>cap</b><br>-          | S6          | -           |  |  |
| <p><b>P670</b></p> <p>Low-profile, two color control knob with integral nut cover</p>                                       | S                | <b>body</b><br>0, 8<br><b>line</b><br>0 - 9<br><b>cap</b><br>-          | D6, S6, D25 | N, S, W, E  |  |  |
| <p><b>P675</b></p> <p>Miniature soft-touch knob Can be used as the top section with P690 to make a dual-concentric pair</p> | S                | <b>body</b><br>0<br><b>line</b><br>0 - 9<br><b>cap</b><br>-             | D4, D6      | N, S, W, E  |  |  |

# Push-Fit Control Knobs - Two Piece

Need a black knob that can be color coded for your specific application? Look no further than the Push-Fit with Cap series of REAN knobs. A wide range of knob styles is available to compliment any design. The caps are offered in any of the ten standard resistor colors – with or without a marker line.



|  | Surface Material | Color  | Fitting | Orientation |   |   |
|--|------------------|--|---------|-------------|---|---|
| <p><b>P102</b></p> <p>Push-on version of the 10mm collet knob series</p>   | H                | <p><b>body</b><br/>0, 8</p> <p><b>line</b><br/>9</p> <p><b>cap</b><br/>-</p> | D4      | N, S, W     |    |    |
| <p><b>P138</b></p> <p>Single-color standard knob<br/>Can be used as the top section with P139 to make a dual-concentric pair</p> | H                | <p><b>body</b><br/>0, 8</p> <p><b>line</b><br/>-</p> <p><b>cap</b><br/>-</p> | D6, S6  | -           |   |   |
| <p><b>P150</b></p> <p>Push-on version of the 15mm collet knob series.</p>  | H                | <p><b>body</b><br/>0</p> <p><b>line</b><br/>9</p> <p><b>cap</b><br/>-</p>    | D25     | N, S, W     |  |  |


|   | Surface Material | Color   | Fitting                  | Orientation |   |   |
|---|------------------|---|--------------------------|-------------|---|---|
| <b>P859</b><br>15mm low-cost control knob             | H                | <b>body</b><br>0<br><b>line</b><br>-<br><b>cap</b><br>- | D4, D6, S6               | -           |    |    |
| <b>P860</b><br>29mm low-cost control knob             | H                | <b>body</b><br>0<br><b>line</b><br>-<br><b>cap</b><br>- | D6, D25                  | -           |   |   |
| <b>P861</b><br>19mm low-cost control knob             | H                | <b>body</b><br>0<br><b>line</b><br>-<br><b>cap</b><br>- | D6, D25, S6              | -           |  |  |
| <b>P862</b><br>19mm control knob with screw fixing    | H                | <b>body</b><br>0<br><b>line</b><br>-<br><b>cap</b><br>- | R25, R4, R6<br>Screw fit | -           |  |  |
| <b>P890</b><br>Low profile 19mm low-cost control knob | H                | <b>body</b><br>0<br><b>line</b><br>-<br><b>cap</b><br>- | D6, S6                   | -           |  |  |



# Dual-Concentric Knobs

Use the top and bottoms together or separately. Want all black with no line or black with white or colored line? Hard or soft touch plastic? Want color coded caps or a one piece knob? These are your choices in the REAN Dual-Concentric line of control knobs. These choices allow for versatility and the screw type shaft allows for ease of use.




|   | Surface Material | Color  | Fitting | Orientation |   |   |
|---|------------------|--|---------|-------------|---|---|
| <p><b>P138</b></p> <p>Used individually or as part of a dual-concentric pair. Styled to complement the P859 range</p>         | H                | <b>body</b><br>0, 8<br><b>line</b><br>-<br><b>cap</b><br>-     | D6, S6  | -           |    |    |
| <p><b>P139</b></p> <p>Dual-concentric base knob partner to P138. (Paired with P138) Features a raised position indicator.</p> | H                | <b>body</b><br>0, 8<br><b>line</b><br>9*<br><b>cap</b><br>-    | C8      | N*          |   |   |
| <p><b>P675</b></p> <p>Miniature control knob. Can be used with the P690 to form a dual-concentric pair.</p>                   | S                | <b>body</b><br>0<br><b>line</b><br>0 - 9<br><b>cap</b><br>-    | D4, D6  | N, S, W, E  |  |  |
| <p><b>P690</b></p> <p>Dual-concentric base knob partner to P675. (Paired with P675)</p>                                       | S                | <b>body</b><br>0, 8<br><b>line</b><br>0 - 9<br><b>cap</b><br>- | C8      | N*          |  |  |

\* Point on the top

N\* Orientation can be North or South - depending on application

# Collet Knobs

The REAN Collet knob series features a screw-fix fitting that allows for freedom of choice when selecting marker line orientation. The four choices of fitting sizes are found on a two color molded body that will not come off its shaft during use. The color coded caps allow for ease of operation and identification.

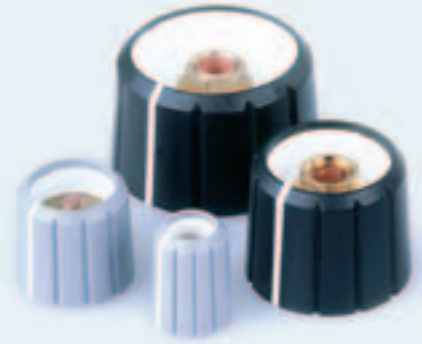

|   | Surface Material | Color   | Fitting          | Orientation |   |   |
|---|------------------|---|------------------|-------------|---|---|
| <b>C100</b><br>High-specification, 10mm, two color collet knob with molded-in marker line | H                | <b>body</b><br>0, 8, 9<br><b>line</b><br>0, 8, 9<br><b>cap</b><br>- | R12, R4          | -           |    |    |
| <b>C150</b><br>High-specification, 15mm, two color collet knob with molded-in marker line | H                | <b>body</b><br>0, 8, 9<br><b>line</b><br>0, 8, 9<br><b>cap</b><br>- | R12, R25, R4, R6 | -           |   |   |
| <b>C210</b><br>High-specification, 21mm, two color collet knob with molded-in marker line | H                | <b>body</b><br>0, 8, 9<br><b>line</b><br>0, 8, 9<br><b>cap</b><br>- | R12, R25, R4, R6 | -           |  |  |
| <b>C280</b><br>High-specification, 28mm, two color collet knob with molded-in marker line | H                | <b>body</b><br>0, 8, 9<br><b>line</b><br>0, 8, 9<br><b>cap</b><br>- | R12, R25, R4, R6 | -           |  |  |

# Caps

While flat surface caps are standard, we now offer a slightly raised (domed) top for several series. All caps are available in any of the ten resistor colors with or without a white or black marker line. These caps work in any application to compliment or color code any two-piece push-on, dual-concentric, or collet knob.



|  | Surface Material | Color   | Fitting | Orientation |  |  |
|--|------------------|---|---------|-------------|--|--|
| <b>T100</b><br>Flat cap for C100 collet knob and P102 10mm push-on knob  | H                | <b>body</b><br>0 - 9<br><b>line</b><br>0, 9, X<br><b>cap</b><br>- | -       | -           |  |  |
| <b>T101</b><br>Domed cap for C100 collet knob and P102 10mm push-on knob | H                | <b>body</b><br>0 - 9<br><b>line</b><br>0, 9, X<br><b>cap</b><br>- | -       | -           |  |  |
| <b>T150</b><br>Flat cap for C150 collet knob and P150 15mm push-on knob  | H                | <b>body</b><br>0 - 9<br><b>line</b><br>0, 9, X<br><b>cap</b><br>- | -       | -           |  |  |
| <b>T151</b><br>Domed cap for C150 collet knob and P150 15mm push-on knob | H                | <b>body</b><br>0 - 9<br><b>line</b><br>0, 9, X<br><b>cap</b><br>- | -       | -           |  |  |
| <b>T210</b><br>Flat cap for C210 collet knob                             | H                | <b>body</b><br>0 - 9<br><b>line</b><br>0, 9, X<br><b>cap</b><br>- | -       | -           |  |  |
| <b>T211</b><br>Domed cap for C210 collet knob                            | H                | <b>body</b><br>0 - 9<br><b>line</b><br>0, 9, X<br><b>cap</b><br>- | -       | -           |  |  |

X = unprinted

|  | Surface Material | Color  | Fitting | Orientation |   |   |
|--|------------------|--|---------|-------------|---|---|
| <b>T280</b><br>Flat cap for C280 collet knob                             | H                | body<br>0 - 9<br>line<br>0, 9, X<br>cap<br>- | -       | -           |    |    |
| <b>T281</b><br>Domed cap for C280 collet knob                            | H                | body<br>0 - 9<br>line<br>0, 9, X<br>cap<br>- | -       | -           |   |  |
| <b>T859</b><br>Flat cap for P859 15mm push-on knob and P138 push-on knob | H                | body<br>0 - 9<br>line<br>0, 9, X<br>cap<br>- | -       | -           |  |  |
| <b>T860</b><br>Flat cap for P860 29mm push-on knob                       | H                | body<br>0 - 9<br>line<br>0, 9, X<br>cap<br>- | -       | -           |  |  |
| <b>T861</b><br>Flat cap for P861 19mm push-on knob                       | H                | body<br>0 - 9<br>line<br>0, 9, X<br>cap<br>- | -       | -           |  |  |

# Sliders


We know that the main objective of a slider knob is ergonomics and aesthetics. With this in mind we offer five different types of sliders from miniature to 15mm that work great and feel good too! All the sliders have molded in marker lines that help eliminate fade and are designed for large and small applications.



|   | Surface Material | Color   | Fitting | Orientation |  |  |
|---|------------------|---|---------|-------------|--|--|
| <p><b>S770</b></p> <p>Profiled two color slider for use in densely populated control surfaces</p>           | H, S             | <p><b>body</b><br/>0 - 9</p> <p><b>line</b><br/>0 - 9</p> <p><b>cap</b><br/>-</p>         | M, K    | -           |  |  |
| <p><b>S771</b></p> <p>Miniature profiled two color slider for use in densely populated control surfaces</p> | H, S             | <p><b>body</b><br/>0 - 9</p> <p><b>line</b><br/>0 - 9</p> <p><b>cap</b><br/>-</p>         | M       | -           |  |  |
| <p><b>S772</b></p> <p>9mm wide, two color slider for use in densely populated control surfaces</p>          | H                | <p><b>body</b><br/>0 - 9, CM, CS</p> <p><b>line</b><br/>0 - 9</p> <p><b>cap</b><br/>-</p> | M       | -           |  |  |
| <p><b>S773</b></p> <p>11mm wide, two color slider knob</p>  | H                | <p><b>body</b><br/>0 - 9, CM, CS</p> <p><b>line</b><br/>0 - 9</p> <p><b>cap</b><br/>-</p> | M, K, P | -           |  |  |
| <p><b>S778</b></p> <p>15mm wide, two color slider knob</p>  | H                | <p><b>body</b><br/>0 - 9</p> <p><b>line</b><br/>0 - 9</p> <p><b>cap</b><br/>-</p>         | M, K, P | -           |  |  |

# Switch Buttons

The REAN line of buttons features textured surface finishes and will complement any other REAN knob or slider. The buttons are available in rectangular, square or circular styles in any of the ten resistor colors and opaque. Custom printing is available.

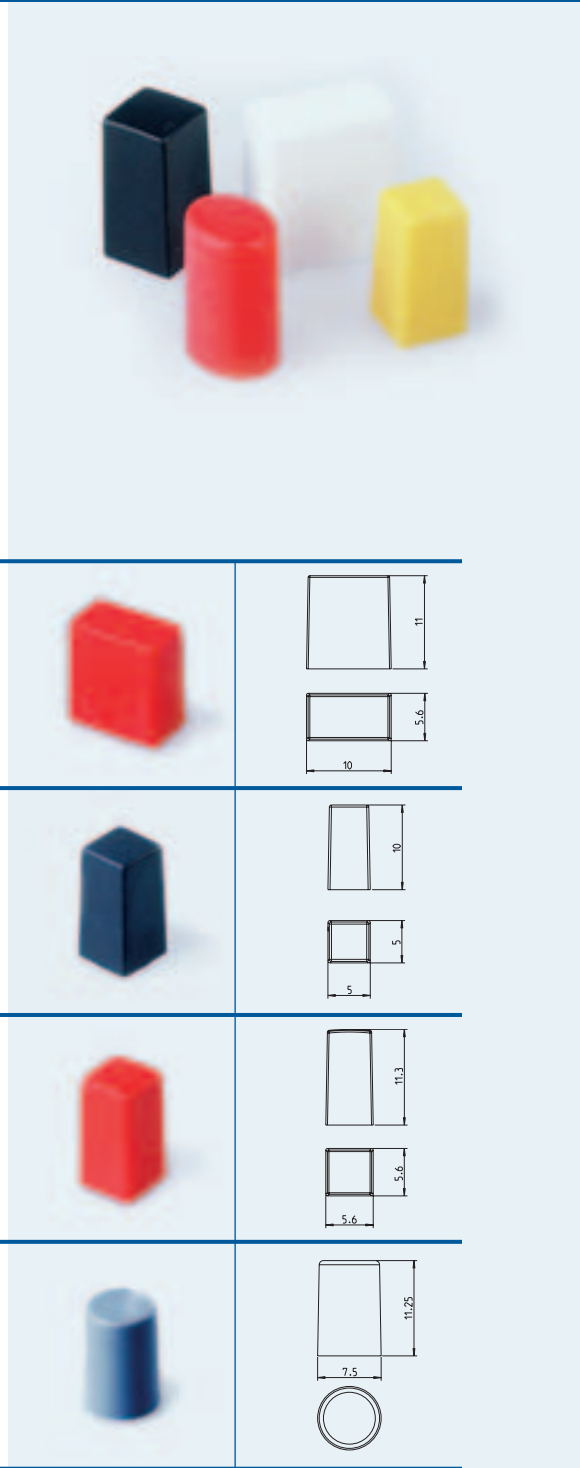

|   | Surface Material | Color                                       | Fitting | Orientation |  |  |
|---|------------------|---|---------|-------------|--|--|
| <b>B120</b><br>Rectangular switch button  | H                | body<br>0 - 9, CLR<br>line<br>-<br>cap<br>- | 28, 33  | -           |  |  |
| <b>B220</b><br>Square, tapered switch button for densely populated control surfaces | H                | body<br>0 - 9, CLR<br>line<br>-<br>cap<br>- | 28, 33  | -           |  |  |
| <b>B222</b><br>Square, tall tapered switch button                                   | H                | body<br>0 - 9, CLR<br>line<br>-<br>cap<br>- | 28, 33  | -           |  |  |
| <b>B225</b><br>Circular switch button   | H                | body<br>0 - 9, CLR<br>line<br>-<br>cap<br>- | 28, 33  | -           |  |  |

## Printing Facilities

We have our own in-house facilities for adding the legends of your choice onto switch buttons.

The advanced process we use provides substantial advances both in longevity and definition over traditional blocking and screen-printing. Our technique involves the transfer of epoxy resin based ink onto the surface of the buttons. There is no restriction regarding the type of characters used – we are happy to work from camera-ready artwork or alternatively we can prepare artwork for you in our own design studios.


Printing options are available. Subject to minimum quantity. Contact factory or sales representative for details.

# Options Key Knob, Slider and Button Options


## Surface Material

**H** = Hard Nylon    **S** = Soft Touch


## Colors

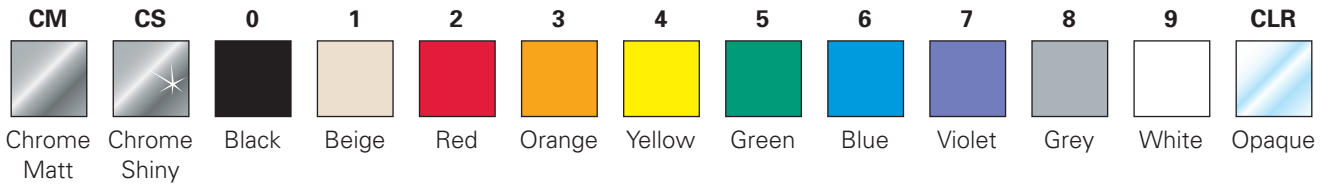

## Knob Fittings

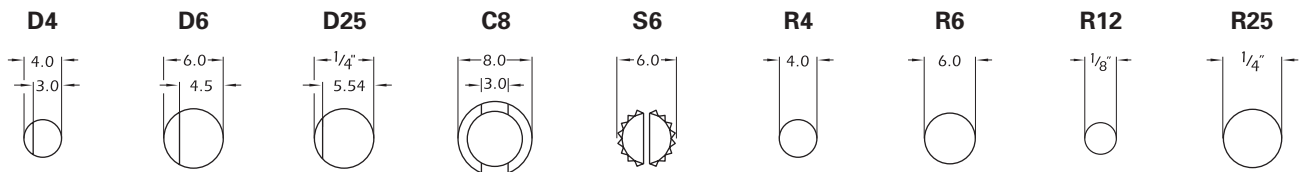


## Slider Fittings

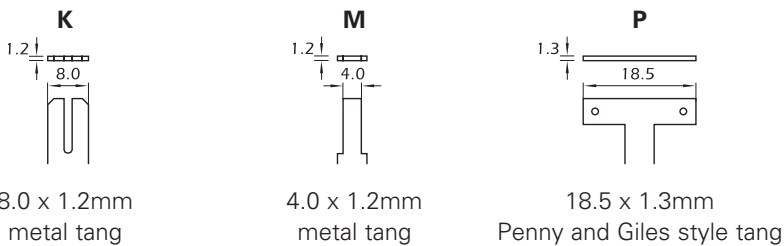

## Switch Button Fittings



## Orientation

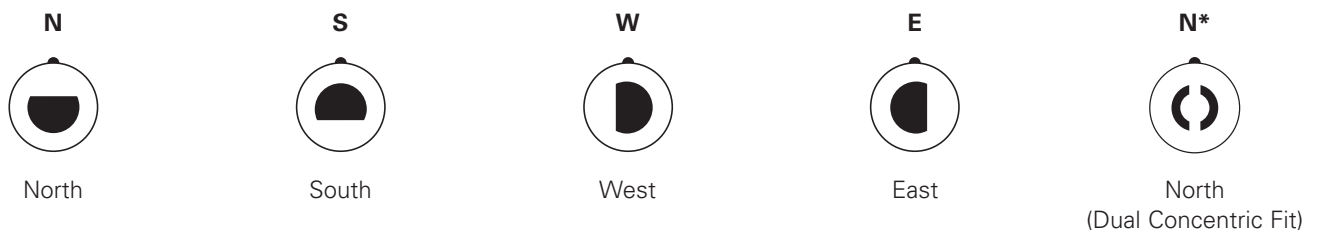

## Part Number Info

**B** = Button    **C** = Collett    **F** = Flexi-Fit    **P** = Push-Fit    **S** = Slider    **T** = Top (cap)

| <b>P</b> | <b>300</b> | <b>H or S</b>    | <b>Body/Line/Cap</b> | <b>Fitting</b> | <b>N, S or W</b> |
|----------|------------|------------------|----------------------|----------------|------------------|
| Type     | Style      | Surface Material | Colors               | Fitting        | Orientation      |
|          |            |                  |                      |                |                  |
| <b>P</b> | <b>XXX</b> | <b>X</b>         | <b>XX(X)</b>         | <b>XX</b>      | <b>X</b>         |

e. g. P - 300 - H - 092 - D6 - W

Other fit and custom color combinations are available to special order. Printing options are also available for buttons (see page 13 «Printing Facilities» for additional information). All special orders are subject to minimum order quantity. Contact factory or sales representative for details.

# Distributors

## Argentina

|                      |   |   |  |
|----------------------|---|---|--|
| ARS Technologies SRL | Pje. Tripoli 4029<br>1419 Buenos Aires, Argentina | info@arstech.com.ar<br>www.arstech.com.ar | Phone +54/11/4574 3666<br>Fax +54/11/4574 1798 |
|----------------------|---|---|--|

## Austria

|                  |   |  |  |
|------------------|---|--|--|
| Wien-Schall GmbH | Krichbaumgasse 25<br>1120 Wien, Austria | org@wienschall.com<br>www.wienschall.com | Phone +43/1/8115 5130<br>Fax +43/1/8115 5180 |
|------------------|---|--|--|

## Bosnia-Herzegovina, Croatia, Slovenia, Macedonia

|                             |  |                       |   |
|-----------------------------|--|-----------------------|---|
| Audio Video Consulting GmbH | Pfongau Mitte 9<br>5202 Neumarkt am Wallersee, Austria | shennermann@avc.co.at | Phone +43/62/1640 210<br>Fax +43/62/1640 2101 |
|-----------------------------|--|-----------------------|---|

## Brazil

|                              |   |  |  |
|------------------------------|---|--|--|
| Santo Angelo Ind. Com. Ltda. | Rua Maria Candida<br>Pereira, 331<br>07041-020 Guarulhos - SP, Brazil | suporte@santoangelo.com.br<br>www.santoangelo.com.br | Phone +55/11/6421 8222<br>Fax +55/11/6421 8797 |
|------------------------------|---|--|--|

## Canada

|                     |   |                           |  |
|---------------------|---|---------------------------|--|
| S.F. Marketing Inc. | 6161 Cypihot<br>St. Laurent<br>H4S 1R3 Quebec, Canada | info@sfm.ca<br>www.sfm.ca | Phone +1/514/856 1919<br>Fax +1/514/856 1920 |
|---------------------|---|---------------------------|--|

## Chile

|                         |   |                       |  |
|-------------------------|---|-----------------------|--|
| Importadora Providencia | San Crescente 113,<br>Las Condes<br>Casilla 91, Correo 10<br>Santiago de Chile, Chile | soimpro@manquehue.net | Phone +56/2/2462 333<br>Fax +56/2/2314 394 |
|-------------------------|---|-----------------------|--|

## Denmark

|             |   |                                      |  |
|-------------|---|--------------------------------------|--|
| Kinovox A/S | Marielundvej 29<br>2730 Herlev, Denmark | kinovox@kinovox.dk<br>www.kinovox.dk | Phone +45/44/53 30 11<br>Fax +45/44/53 30 06 |
|-------------|---|--------------------------------------|--|

## Finland

|                          |  |                                       |   |
|--------------------------|--|---------------------------------------|---|
| Noretron Components Ltd. | Mankkaantie 32<br>02631 Espoo, Finland | myynti@noretron.fi<br>www.noretron.fi | Phone +358/9/52 59 330<br>Fax +358/9/52 59 3352 |
|--------------------------|--|---------------------------------------|---|

## France

|                |  |   |  |
|----------------|--|---|--|
| Neutrik France | 13 rue du Parchamp<br>92100 Boulogne-Billancourt, France | info@neutrik-france.com<br>www.neutrik-france.com | Phone +33 1 41 31 67 50<br>Fax +33 1 41 31 05 11 |
|----------------|--|---|--|

## Germany

|                        |   |                                   |  |
|------------------------|---|-----------------------------------|--|
| Neutrik Vertriebs GmbH | Felix-Wankel-Strasse 1<br>85221 Dachau, Germany | info@neutrik.de<br>www.neutrik.de | Phone +49/8131/28 08 90<br>Fax +49/8131/28 08 30 |
|------------------------|---|-----------------------------------|--|

## Great Britain

|                 |  |  |  |
|-----------------|--|--|--|
| Neutrik UK Ltd. | Westridge Business Park<br>Cothey Way<br>PO33 1QT Ryde<br>Isle of Wight, Great Britain | sales@neutrik.co.uk<br>www.neutrik.co.uk | Phone +44/1983/811 441<br>Fax +44/1983/811 439 |
|-----------------|--|--|--|

## Greece

|                 |   |                                       |  |
|-----------------|---|---------------------------------------|--|
| Bon Studio S.A. | 6, Zaimi Street<br>10683 Athens, Greece | bon@bonstudio.gr<br>www.bonstudio.com | Phone +30/10/38 09 605<br>Fax +30/10/38 45 755 |
|-----------------|---|---------------------------------------|--|

## Hongkong

|                         |   |   |  |
|-------------------------|---|---|--|
| Hapworld Hong Kong Ltd. | 20th Floor, Chai Wan Industrial<br>City Phase 2,<br>70 Wing Tai Road<br>Chai Wan, China | hapworld@hapworld.com.hk<br>www.hapworld.com.hk | Phone +852/2/89 89 366<br>Fax +852/2/89 67 603 |
|-------------------------|---|---|--|

## Hungary, Slovakia, Czech Republic

|                     |  |                   |  |
|---------------------|--|-------------------|--|
| BaSys Informatik AG | Leisackerstrasse 4<br>4566 Halten, Switzerland | schweiz@basys.net | Phone +41/32/675 55 25<br>Fax +41/32/675 55 80 |
|---------------------|--|-------------------|--|

## India

|                                |   |  |  |
|--------------------------------|---|--|--|
| AVF Distributors (I) Pvt. Ltd. | 208, Jogani Ind. Complex,<br>Bldg. No. 6, Near ATI, Chunabhatti<br>400022 Mumbai, India | sales@avfindia.com<br>www.avfindia.com | Phone +91/22/2 528 7186<br>Fax +91/22/2 528 7190 |
|--------------------------------|---|--|--|

## Indonesia

|                    |   |                  |  |
|--------------------|---|------------------|--|
| Santika Multi Jaya | Jl. Danau Sunter Selatan<br>Blok 0-3 No. 60, Sunter<br>14350 Jakarta, Indonesia | andre@cbn.net.id | Phone +62/21/65 06 040<br>Fax +62/21/65 08 804 |
|--------------------|---|------------------|--|

## Israel

|                                |   |  |  |
|--------------------------------|---|--|--|
| Sontronics Electr. Equip. Ltd. | 2, Y. Bin Nun St.<br>P.O. Box 2090<br>51400 Bnei Brak, Israel | sales@sontronics.co.il<br>www.sontronics.co.il | Phone +972/3/57 05 223<br>Fax +972/3/61 99 297 |
|--------------------------------|---|--|--|

## Italy

|          |  |   |   |
|----------|--|---|---|
| A&DT SRL | Via Solferino 54<br>20052 Monza, Italy | info@adt-online.it<br>www.audioequipment.it | Phone +39/039/21 69 21<br>Fax +39/039/21 03 506 |
|----------|--|---|---|

## Japan

|                 |  |   |  |
|-----------------|--|---|--|
| Neutrik Limited | Sakuramasamune-Higashinohonbashi<br>Bldg. 3-12-12, Higashi-Nihonbashi<br>103-0004 Tokyo, Japan | mail@neutrik.co.jp<br>www.neutrik.co.jp | Phone +81/3/3663 47 33<br>Fax +81/3/3663 47 96 |
|-----------------|--|---|--|

## Korea

|                    |  |  |   |
|--------------------|--|--|---|
| Sovico Corporation | 1027-5, Bangbae3-dong,<br>Seocho-ku,<br>C.P.O. BOX 375<br>137-851 Seoul, Korea | annie@sovico.co.kr<br>www.sovico.co.kr | Phone +82/2/21062878<br>Fax +82/2/5863721 |
|--------------------|--|--|---|



**Lebanon**

|       |  |                                     |              |                                  |
|-------|--|-------------------------------------|--------------|----------------------------------|
| Eltek | Fanar Street, Eltek 711 Bldg.<br>Beirut, Lebanon | eltek@dm.net.lb<br>www.eltek.com.lb | Phone<br>Fax | +961/187 26 66<br>+961/359 82 22 |
|-------|--|-------------------------------------|--------------|----------------------------------|

**Mexico**

|                   |  |                      |              |                                      |
|-------------------|--|----------------------|--------------|--------------------------------------|
| Vari S.A. De C.V. | Palenque No. 663<br>Col. Vertiz Narvarte<br>03600 Mexico, DF, Mexico | vari@varinter.com.mx | Phone<br>Fax | +52/55/5605 9555<br>+52/55/5605 9656 |
|-------------------|--|----------------------|--------------|--------------------------------------|

**New Zealand**

|              |   |                                      |              |                                  |
|--------------|---|--------------------------------------|--------------|----------------------------------|
| CINZ Limited | 44 Pharazyn St., Lower Hutt<br>P.O. Box 38-099<br>Wellington Mail Centre<br>Wellington, New Zealand | sales@candi.co.nz<br>www.candi.co.nz | Phone<br>Fax | +64/4/566 3222<br>+64/4/566 3722 |
|--------------|---|--------------------------------------|--------------|----------------------------------|

**Norway**

|           |  |                               |              |                                    |
|-----------|--|-------------------------------|--------------|------------------------------------|
| Benum A/S | Haakon den godes vei 14<br>Postboks 145, Vinderen<br>0319 Oslo 3, Norway | post@benum.no<br>www.benum.no | Phone<br>Fax | +47/22/13 99 00<br>+47/22/14 82 59 |
|-----------|--|-------------------------------|--------------|------------------------------------|

**Philippines**

|                            |   |  |              |                                    |
|----------------------------|---|--|--------------|------------------------------------|
| Audiophile Components Inc. | 1142 Pres. Quirino Ave., Ext.<br>Paco, Manila, Philippines 1007 | audioph@audiophilecomponents.com<br>www.audiophilecomponents.com | Phone<br>Fax | +63/2/588 09 19<br>+63/2/564 17 20 |
|----------------------------|---|--|--------------|------------------------------------|

**Poland**

|                          |   |   |              |                                      |
|--------------------------|---|---|--------------|--------------------------------------|
| Konsbud Audio Sp. Z O.O. | ul. Gajdy 24<br>02-878 Warszawa, Poland | info@konsbud-audio.com.pl<br>www.konsbud-audio.com.pl | Phone<br>Fax | +48/22/644 30 38<br>+48/22/648 02 36 |
|--------------------------|---|---|--------------|--------------------------------------|

**Portugal**

|               |  |                                       |              |                                      |
|---------------|--|---------------------------------------|--------------|--------------------------------------|
| Arestel, S.A. | Pct. Av. Mario Moutinho<br>Lote 1528-cv<br>1400-136 Lisboa, Portugal | avinagre@arestel.pt<br>www.arestel.pt | Phone<br>Fax | +351/21/303 0850<br>+351/21/301 6221 |
|---------------|--|---------------------------------------|--------------|--------------------------------------|

**Russia**

|          |  |                             |              |                                    |
|----------|--|-----------------------------|--------------|------------------------------------|
| I.S.P.A. | 2-aya<br>Zvenigorodskaya str. 13, 4th Floor<br>123022 Moscow, Russia | ispa@ispa.ru<br>www.ispa.ru | Phone<br>Fax | +7/095/784 7575<br>+7/095/956 2309 |
|----------|--|-----------------------------|--------------|------------------------------------|

**Singapore, Vietnam, Myanmar, Brunei, Bangladesh, Malaysia**

|                            |                                     |                       |              |                                |
|----------------------------|-------------------------------------|-----------------------|--------------|--------------------------------|
| Studer S.E. Asia Pte. Ltd. | 273 Outram Road<br>169063 Singapore | studer@pacific.net.sg | Phone<br>Fax | +65/22 55 115<br>+65/22 55 005 |
|----------------------------|-------------------------------------|-----------------------|--------------|--------------------------------|

**South Africa**

|                         |   |                     |              |                                    |
|-------------------------|---|---------------------|--------------|------------------------------------|
| Wild & Marr (Pty.) Ltd. | 49, 11th Road Kew 2090,<br>P.O. Box 112 Bramley 2018<br>2018 Johannesburg, South Africa | wildmarr@icon.co.za | Phone<br>Fax | +27/11/887 5271<br>+27/11/887 4059 |
|-------------------------|---|---------------------|--------------|------------------------------------|

**Spain**

|                   |   |                          |              |                                      |
|-------------------|---|--------------------------|--------------|--------------------------------------|
| Neotecnica S.A.E. | Marques de Urquijo, 44<br>28008 Madrid, Spain | neotecnica@neotecnica.es | Phone<br>Fax | +34/91/54 20 900<br>+34/91/54 27 742 |
|-------------------|---|--------------------------|--------------|--------------------------------------|

**Sweden**

|               |   |   |              |                                      |
|---------------|---|---|--------------|--------------------------------------|
| Sennheiser AB | Pontonjärsgatan 6,<br>BP 50056<br>10422 Stockholm, Sweden | mail@sennheiser.se<br>www.sennheiser.se | Phone<br>Fax | +46/8/566 16 400<br>+46/8/566 16 490 |
|---------------|---|---|--------------|--------------------------------------|

**Switzerland**

|                   |  |                                      |              |                                    |
|-------------------|--|--------------------------------------|--------------|------------------------------------|
| Neutrik Zürich AG | Steinackerstrasse 35<br>8902 Urdorf, Switzerland | neutrik@neutrik.ch<br>www.neutrik.ch | Phone<br>Fax | +41/1/736 50 10<br>+41/1/736 50 11 |
|-------------------|--|--------------------------------------|--------------|------------------------------------|

**Taiwan**

|                      |  |                         |              |  |
|----------------------|--|-------------------------|--------------|--|
| Taisheng Trading Co. | 24, Jilin Road<br>10424 Taipei, Taiwan | audiotek@ms19.hinet.net | Phone<br>Fax | +886/2/2531 38 02<br>+886/2/2563 72 78 |
|----------------------|--|-------------------------|--------------|--|

**Thailand**

|                            |  |                     |              |                                  |
|----------------------------|--|---------------------|--------------|----------------------------------|
| Vichai Trading Co., R.O.P. | 573/2<br>Soi Ramkamhaeng 39<br>Prachauthit Rd., Bangkok<br>10310 Bangkok, Thailand | victorco@ksc.th.com | Phone<br>Fax | +662/55 90 956<br>+662/55 90 959 |
|----------------------------|--|---------------------|--------------|----------------------------------|

**Turkey**

|                   |  |                                    |              |  |
|-------------------|--|------------------------------------|--------------|--|
| SF Dis Ticaret AS | Palanga Caddesi,<br>No. 44-7<br>80840 Ortakoy-Istanbul, Turkey | webmaster@sftr.com<br>www.sftr.com | Phone<br>Fax | +90/212/22 79 625<br>+90/212/22 79 654 |
|-------------------|--|------------------------------------|--------------|--|

**Ukraine**

|            |   |                 |              |                                      |
|------------|---|-----------------|--------------|--------------------------------------|
| Real Music | 17, Lva Tolstogo str.<br>270000 Odessa, Ukraine | rm@tm.odessa.ua | Phone<br>Fax | +380/48/2347 382<br>+380/48/2265 973 |
|------------|---|-----------------|--------------|--------------------------------------|

**USA**

|                  |   |   |              |                                      |
|------------------|---|---|--------------|--------------------------------------|
| Neutrik USA Inc. | 195 Lehigh Avenue<br>08701-4527 Lakewood, USA | info@neutrikusa.com<br>www.neutrikusa.com | Phone<br>Fax | +1/732/901 94 88<br>+1/732/901 96 08 |
|------------------|---|---|--------------|--------------------------------------|

**Venezuela**

|                    |  |   |              |                                      |
|--------------------|--|---|--------------|--------------------------------------|
| Audio Concept C.A. | Calle Vargas, EDIF. Siete<br>Piso 1, Boleita Norte<br>Caracas, Venezuela | info@audioconcept.com.ve<br>www.audioconcept.com.ve | Phone<br>Fax | +58/21/2237 7203<br>+58/21/2237 9480 |
|--------------------|--|---|--------------|--------------------------------------|

