

Product information

95 41 165

Cable Shears



- Multifunctional tool for working on NYM cable from 3 x 1.5 mm² to 5 x 2.5 mm² (cutting and stripping)
- Universal stripping area for both solid conductor cross-sections
- Reliable alignment of the cable in the stripping area due to V-shaped blade geometry
- For cutting copper and aluminium single conductors as well as multiple stranded cables
- Clean and smooth cut without crushing and deformation
- Not suitable for steel wire and hard drawn copper conductors
- Precision-ground, hardened blades
- Easy cutting with one-hand operation
- With guard
- Adjustable bolted joint, self-retaining screw
- High-grade special tool steel, forged, oil-hardened


MM

General	
Article No.	95 41 165
EAN	4003773078609
Shears	burnished
Handles	plastic coated
weight	220 g
Dimensions	165 x 42 x 15 mm
Reach	Nein
RohS	no

Technical details	
Style	4
Cutting capacity copper cable, multiple-stranded	35 mm ²
Cutting capacity copper cable, multiple-stranded	Ø 12 mm
AWG	1 / 0

Classification	
eCl@ss 5.1.4	21040601
ETIM 5.0	EC000142
ETIM 6.0	EC000142
proficl@ss 6.0	EAD256c001
UNSPSC 13.1	27111506

technical change and errors excepted

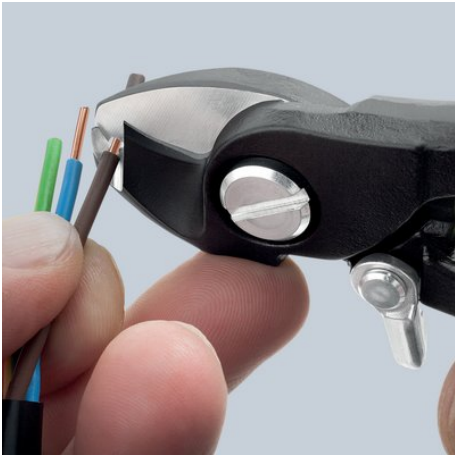

95 41 165: with stripping function



95 41 165