


EZ9ES2R5R5DMRE

2+5+5 way Easy9 Consumer Unit - 1x 100A main Sw
+ 2x 80A RCCB + 8x MCBs

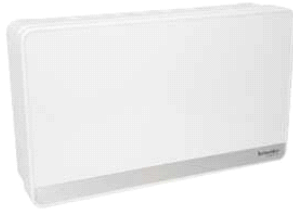

Main

Range of product	Easy9
Product or component type	Split consumer unit
Enclosure type	Metal enclosure
Provided equipment	Earth/neutral terminal block Earth/neutral terminal block 1 miniature circuit breaker (MCB) 16 A 1 miniature circuit breaker (MCB) 40 A Busbar 2 RCCB 80 A 1 switch disconnecter 100 A 3 miniature circuit breaker (MCB) 6 A 3 miniature circuit breaker (MCB) 32 A
Type of front cover	Plain
Product compatibility	Easy9 MCB Easy9 RCCB Easy9 RCBO Easy9 switch Easy9 SPD

Complementary

Enclosure mounting	Flush Surface
Number of 18 mm modules per row	12
Total number of 18 mm modules	12
Number of horizontal rows	1
Number of ways	12
Enclosure material	Metal
[In] rated current	100 A
[Ue] rated operational voltage	230/240 V
Network frequency	50 Hz
Type of rail	DIN
Cable entry	Knock-out
Cable cross section	1...25 mm ² incoming
Comb busbar and distribution block compatibility	YES
Product weight	8.35 kg
Height	276.8 mm
Width	464.8 mm
Depth	119.55 mm
Colour	White

Environment

standards	BS EN 61439-3 BS 7671: amendment 3
standards	BS EN 61439-3
IP degree of protection	IPxx D on top IP3x with cover
IK degree of protection	IK05
overvoltage category	II